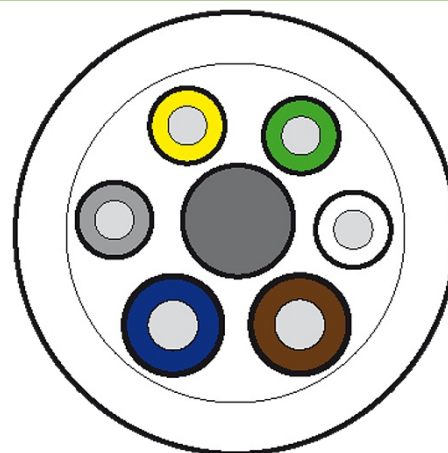


50M MAIN CABLE PUR-OB 4*0,34+2*0,75

4-way distribution boxes M8

4 × 0.34 + 2 × 0.75 mm²[Link to Product](#)**Illustration**

Product may differ from Image

Cables

Cable number	334
No./diameter of wires	4 × 0.34 + 2 × 0.75 mm ²
Wire isolation	TPE-E
C-track properties	5 Mio.
Jacket Color	gray
Material (jacket)	PUR (UL/CSA)
Outer Ø	7.6 mm ±5%
Bend radius (fixed)	5 × outer Ø
Bend radius (moving)	10 × outer Ø
Temperature range (fixed)	-40...+80 °C
Temperature range (mobile)	-5...+60 °C
Color (jacket)	gray
Approval (cable)	UL (AWM-Style 20233), CSA

Commercial data

country of origin	IT
customs tariff number	85444995
EAN	4048879057318
eClass	27062011
Packaging unit	1