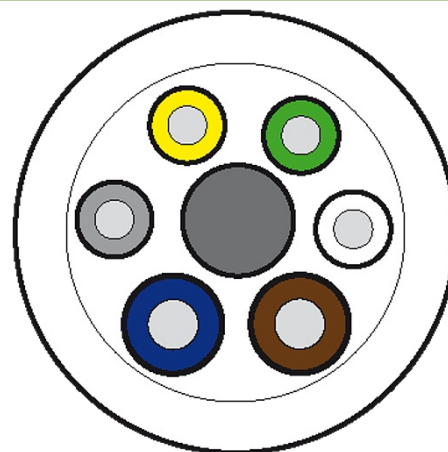


50M MAIN CABLE PUR/PVC 4X0,34+2X0,75

for 4-way distribution boxes M8

4 × 0.34 + 2 × 0.75 mm²

PUR/PVC

[Link to Product](#)**Illustration**

Product may differ from Image

Cables

Cable number	337
No./diameter of wires	4 × 0.34 + 2 × 0.75 mm ²
Wire isolation	PVC (br, bl, ye, wh, gn, gr)
C-track properties	2 Mio.
Jacket Color	gray
Material (jacket)	PUR/PVC
Outer Ø	6.9 mm ±5%
Bend radius (fixed)	5 × outer Ø
Bend radius (moving)	10 × outer Ø
Temperature range (fixed)	-30...+80 °C
Temperature range (mobile)	-5...+60 °C
Color (jacket)	gray

Commercial data

country of origin	IT
customs tariff number	85444995
EAN	4048879057301
eClass	27062011
Packaging unit	1