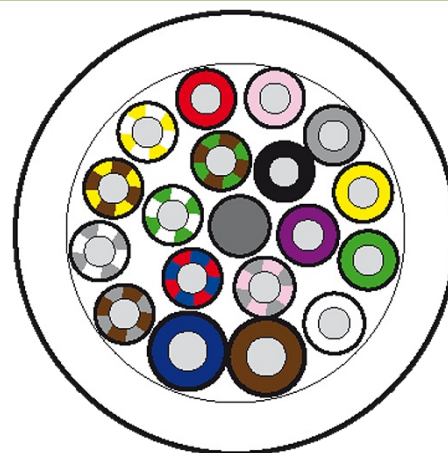


50M MAIN CABLE PUR-OB 16*0,34+2*0,75

8-way distribution boxes M8

16× 0.34 + 2× 0.75 mm²[Link to Product](#)**Illustration**

Product may differ from Image

Cables

Cable number	396
No./diameter of wires	16× 0.34 + 2× 0.75 mm ²
C-track properties	5 Mio.
Jacket Color	gray
Material (jacket)	PUR (UL/CSA)
Outer Ø	10.4 mm ±5%
Bend radius (fixed)	5× outer Ø
Bend radius (moving)	10× outer Ø
Temperature range (fixed)	-40...+80 °C
Temperature range (mobile)	-5...+60 °C

Commercial data

country of origin	IT
customs tariff number	85444995
EAN	4048879057134
eClass	27062011
Packaging unit	1