

MVP12, 4XM12, UNIVERSAL, SET

Pins wired 1:1 to terminal

4-way UNIVERSAL

Screw plug-in terminals

all 5 contacts of the M12 females separately carried on terminals

Replaces identical product (Art.No. 276625)


 
 
 
 
Separation contact 5 possible by removable plug links

Plastic housings with good resistance against chemicals and oils.


The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

M12-Females 5-pole

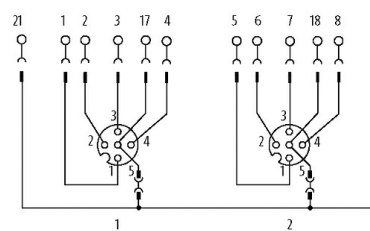

free arrangeable, contact 1:1 on terminals
for 5 signals per port, possibility to bridge each PIN5

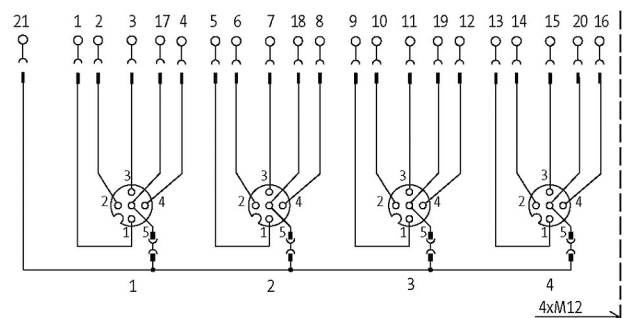

Product may differ from Image

Approvals



Contact Layout

PIN 1	(S1)
PIN 2	(S2)
PIN 3	(S3)
PIN 4	(S4)
PIN 5	(S5)/(Earth)

General data

Temperature range	-20...+80 °C
-------------------	--------------


Technical Data

Operating voltage	max. 42 V AC/DC
Operating current per contact	max. 4 A
Total current	max. 8 A
Connection	Screw plug-in terminals: max. 1.5 mm ² (AWG 16)
Protection	IP65/IP67
Housing	Plastic, flame retardant

Commercial data

country of origin	DE
customs tariff number	85369010
EAN	4048879353434
eClass	27279219
Packaging unit	1

Sketch

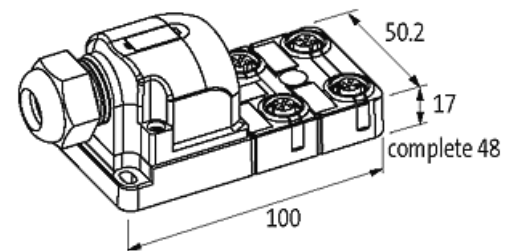

Product may differ from Image