

EXACT8, 10XM8, 4POLE, MOULDED CABLE

5.0m PUR 20x0,34+2x0,75

10-way, 4-pole

for NPN signals 24 V DC

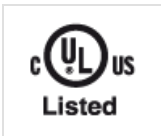
Further cable lengths on request.

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Product may differ from Image

Approvals**Contact Layout**

| | |
|-------------|--|
| PIN 1 | (+) |
| PIN 2 | (NC)/(S2) |
| PIN 3 | (-) |
| PIN 4 | (NO)/(S1) |
| LED display | LED (green): Power / LED (yellow): (S1) / LED (white): Signal (S2) |

General data

Temperature range -20...+80 °C, depending on cable quality

Cables

| | |
|----------------------------|------------------------------------|
| Cable number | 411 |
| No./diameter of wires | 20x 0.34 + 2x 0.75 mm ² |
| C-track properties | 5 Mio. |
| Jacket Color | gray |
| Material (jacket) | PUR (UL/CSA) |
| Outer Ø | 11.3 mm ±5% |
| Bend radius (fixed) | 5x outer Ø |
| Bend radius (moving) | 10x outer Ø |
| Temperature range (fixed) | -40...+80 °C |
| Temperature range (mobile) | -5...+60 °C |
| Approval (cable) | UL (AWM-Style 20233), CSA |

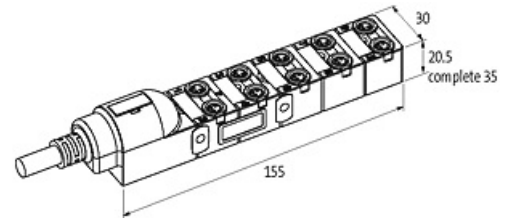
Technical Data

| | |
|-------------------|---------|
| Operating voltage | 24 V DC |
|-------------------|---------|

| | |
|-------------------------------|--------------------------|
| Operating current per contact | max. 2 A |
| Total current | max. 8 A |
| Signal per port | 2 |
| Protection | IP65/IP67 |
| Housing | Plastic, flame retardant |
| Locking of ports | Screw thread (M8×1 mm) |

Commercial data

| | |
|-----------------------|---------------|
| country of origin | DE |
| customs tariff number | 85444290 |
| EAN | 4048879056649 |
| eClass | 27279219 |
| Packaging unit | 1 |

Sketch

Product may differ from Image