

**EXACT8, 4XM8, 3 POLE BASIC HOUSING, NPN-LED'S**

Without connector cable

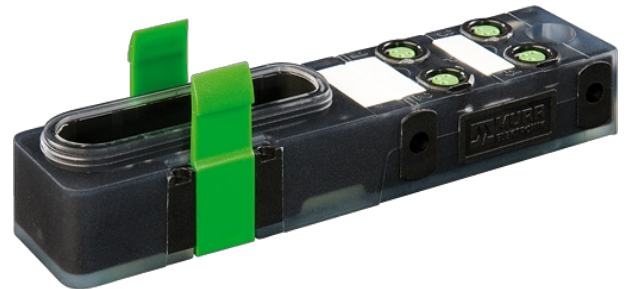
4-way, 3-pole

Inline face or side mounting

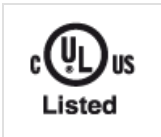
for NPN signals 24 V DC

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Product may differ from Image

**Approvals****Contact Layout**

PIN 1	(+)
PIN 3	(-)
PIN 4	(NO)/(S1)
LED display	LED (green): Power / LED (yellow): (S1)

**General data**

Temperature range	-20...+70 °C, depending on cable quality
-------------------	--

**Technical Data**

Operating voltage	24 V DC
Operating current per contact	max. 2 A
Total current	max. 8 A
Protection	IP65/IP67

**Commercial data**

country of origin	DE
customs tariff number	85369010
EAN	4048879056601
eClass	27279219
Packaging unit	1