

**EXACT8, 4XM8, 3 POLE PRE-WIRED CABLE**

10.0m PUR/PVC 4\*0,34+2\*0,75

4-way, 3-pole


Further cable lengths on request.

Plastic housings with good resistance against chemicals and oils.


 
The resistance to aggressive media should be individually tested for your application. Further details on request.

PUR/PVC

10.0 m

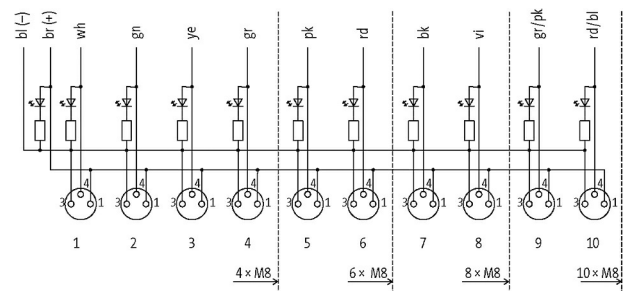**[Link to Product](#)****Illustration**

M8-Females 3-pole

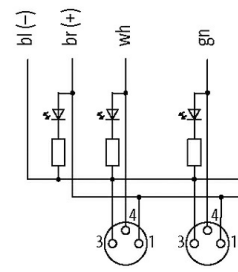

for 1 signal per port

Product may differ from Image

**Approvals**

**Contact Layout**

|             |   |
|-------------|---|
| PIN 1       | (+)                                     |
| PIN 3       | (-)                                     |
| PIN 4       | (NO)/(S1)                               |
| LED display | LED (green): Power / LED (yellow): (S1) |

**General data**

|                   |  |
|-------------------|--|
| Temperature range | -20...+80 °C, depending on cable quality |
|-------------------|--|

**Cables**


|                            |                                   |
|----------------------------|-----------------------------------|
| Cable number               | 337                               |
| No./diameter of wires      | 4× 0.34 + 2× 0.75 mm <sup>2</sup> |
| Wire isolation             | PVC (br, bl, ye, wh, gn, gr)      |
| C-track properties         | 2 Mio.                            |
| Jacket Color               | gray                              |
| Material (jacket)          | PUR/PVC                           |
| Outer Ø                    | 6.9 mm ±5%                        |
| Bend radius (fixed)        | 5× outer Ø                        |
| Bend radius (moving)       | 10× outer Ø                       |
| Temperature range (fixed)  | -30...+80 °C                      |
| Temperature range (mobile) | -5...+60 °C                       |
| Color (jacket)             | gray                              |

**Technical Data**

|                               |                          |
|-------------------------------|--------------------------|
| Operating voltage             | 24 V DC                  |
| Operating current per contact | max. 2 A                 |
| Total current                 | max. 8 A                 |
| Signal per port               | 1 - (31-32)              |
| Locking of ports              | Screw thread (M8×1 mm)   |
| Protection                    | IP65/IP67                |
| Housing                       | Plastic, flame retardant |

**Commercial data**

|                       |               |
|-----------------------|---------------|
| country of origin     | DE            |
| customs tariff number | 85444290      |
| EAN                   | 4048879056526 |
| eClass                | 27279219      |
| Packaging unit        | 1             |

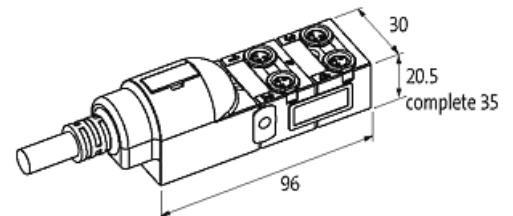**Sketch**

Product may differ from Image