

EXACT8, 4XM8, 3 POLE PRE-WIRED CABLE

15.0m PUR/PVC 4*0,34+2*0,75

4-way, 3-pole


Further cable lengths on request.

Plastic housings with good resistance against chemicals and oils.


 
The resistance to aggressive media should be individually tested for your application. Further details on request.

PUR/PVC

15.0 m

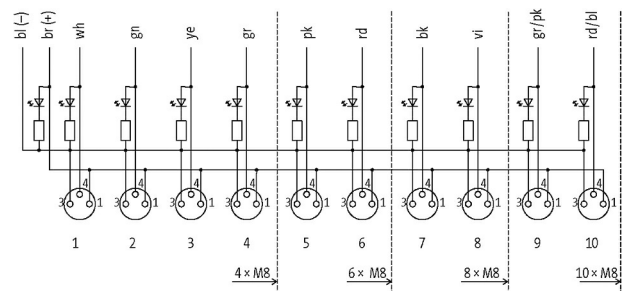[Link to Product](#)**Illustration**

M8-Females 3-pole

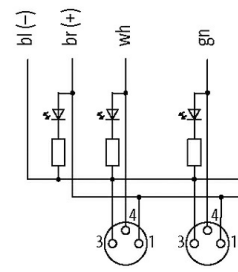

for 1 signal per port

Product may differ from Image

Approvals

Contact Layout

PIN 1	(+)
PIN 3	(-)
PIN 4	(NO)/(S1)
LED display	LED (green): Power / LED (yellow): (S1)

General data

Temperature range	-20...+80 °C, depending on cable quality
-------------------	--

Cables


Cable number	337
No./diameter of wires	4× 0.34 + 2× 0.75 mm ²
Wire isolation	PVC (br, bl, ye, wh, gn, gr)
C-track properties	2 Mio.
Jacket Color	gray
Material (jacket)	PUR/PVC
Outer Ø	6.9 mm ±5%
Bend radius (fixed)	5× outer Ø
Bend radius (moving)	10× outer Ø
Temperature range (fixed)	-30...+80 °C
Temperature range (mobile)	-5...+60 °C
Color (jacket)	gray

Technical Data

Operating voltage	24 V DC
Operating current per contact	max. 2 A
Total current	max. 8 A
Signal per port	1 - (31-32)
Locking of ports	Screw thread (M8×1 mm)
Protection	IP65/IP67
Housing	Plastic, flame retardant

Commercial data

country of origin	DE
customs tariff number	85444290
EAN	4048879056519
eClass	27279219
Packaging unit	1

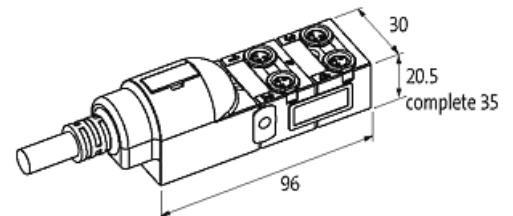Sketch

Product may differ from Image