

EXACT8, 4XM8, 3 POLE

Conn.M12 12 pole


4-way, 3-pole

M12 (12-pole)


Inline face or side mounting

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

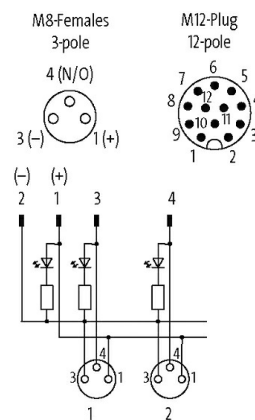
[Link to Product](#)**Illustration**

for 1 signal per port

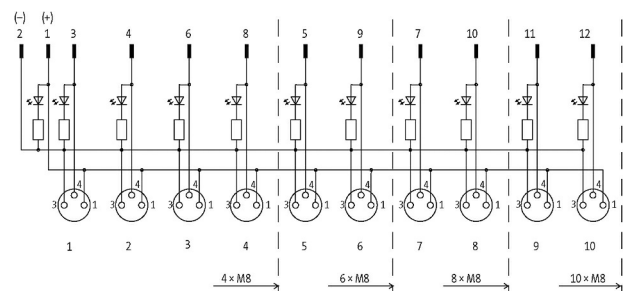

Product may differ from Image

Approvals

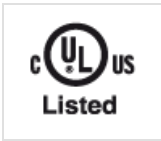

Contact Layout

PIN 1	(+)
PIN 3	(-)
PIN 4	(NO)/(S1)
LED display	LED (green): Power / LED (yellow): (S1)

General data

Temperature range	-20...+70 °C, depending on cable quality
-------------------	--


Technical Data

Operating voltage	24 V DC
Operating current per contact	max. 1.5 A
Protection	IP67 inserted and tightened (EN 60529)
Housing	Plastic, flame retardant

Commercial data

country of origin	DE
customs tariff number	85369010
EAN	4048879056311
eClass	27279219
Packaging unit	1

Sketch

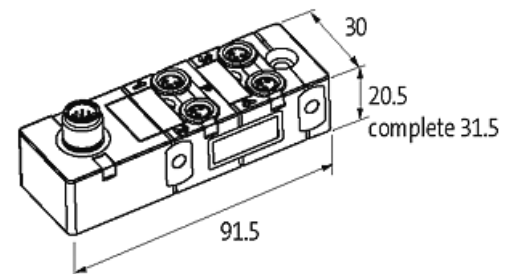

Product may differ from Image