

**EXACT8, 4XM8, 4 POLE MOULDED CABLE**

10.0m PUR 8x0,34+2x0,75 NPN-LED's

4-way, 4-pole

for NPN signals 24 V DC

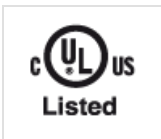
Further cable lengths on request.

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Product may differ from Image

**Approvals****Contact Layout**

PIN 1	(+)
PIN 2	(NC)/(S2)
PIN 3	(-)
PIN 4	(NO)/(S1)
LED display	LED (green): Power / LED (yellow): (S1) / LED (white): Signal (S2)

**General data**

Temperature range -20...+80 °C, depending on cable quality

**Cables**

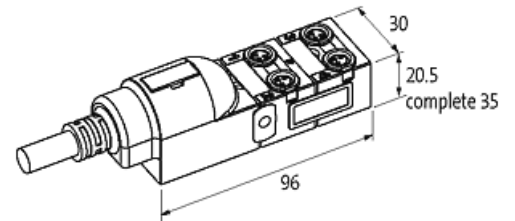
Cable number	360
No./diameter of wires	8x 0.34 + 2x 0.75 mm <sup>2</sup>
Wire isolation	TPE (brgn, whgn, rdbl, grpk, gr, ye, gn, wh+br, bl)
C-track properties	5 Mio.
Jacket Color	gray
Material (jacket)	PUR (UL/CSA)
Outer Ø	9.2 mm ±5%
Bend radius (fixed)	5x outer Ø
Bend radius (moving)	10x outer Ø
Temperature range (fixed)	-40...+80 °C
Temperature range (mobile)	-5...+60 °C
Color (jacket)	gray

**Technical Data**

Operating voltage	24 V DC
Operating current per contact	max. 2 A
Total current	max. 8 A
Protection	IP65/IP67
Housing	Plastic, flame retardant
Locking of ports	Screw thread (M8×1 mm)

**Commercial data**

country of origin	DE
customs tariff number	85444290
EAN	4048879056182
eClass	27279219
Packaging unit	1

**Sketch**

Product may differ from Image