

EXACT12, 4XM12, 4 POLE

Conn.M12 8pole

4-way

4-pole (port 3+4)

5-pole (port 1+2)



M12 plug connection, 8-pole

with LED for digital PNP-signals 24 V DC

Plastic housings with good resistance against chemicals and oils.


[Link to Product](#)

Illustration

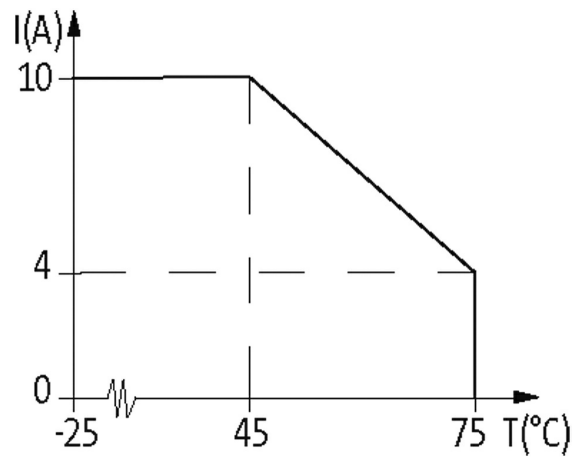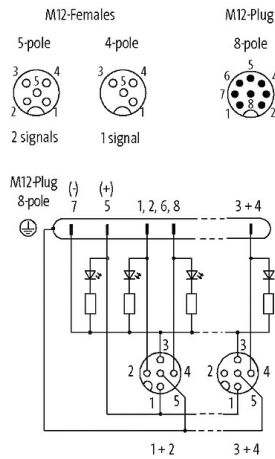

Product may differ from Image

Approvals

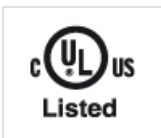

Contact Layout

PIN 1	(+)
PIN 2	(NC)/(S2)
PIN 3	(-)
PIN 4	(NO)/(S1)
PIN 5	(Earth)

LED display LED (green): Power / LED (yellow): (S1) / LED (white): Signal (S2)

General data

Temperature range -20...+70 °C

Technical Data

Operating voltage 24 V DC

Operating current per contact max. 2 A

Total current max. 2 A

Protection IP65/IP67

Housing Plastic, flame retardant

Commercial data

country of origin DE


customs tariff number 85369010

EAN 4048879323086

eClass 27279219

Packaging unit 1

Sketch

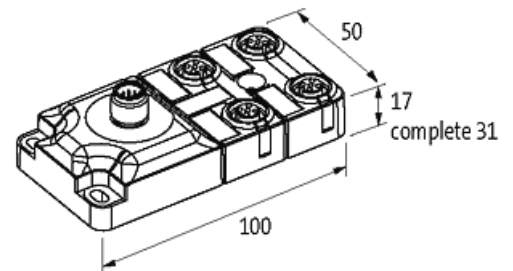

Product may differ from Image