

EXACT8, 6XM8, 4 POLE PLUG. CAP, SPRING-TERM.

3.0m PUR 12x0.34+2x0,75, UL/CSA

6-way, 4-pole

Further cable lengths on request.

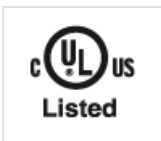
Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

3.0 m

[Link to Product](#)**Illustration**

Product may differ from Image

Approvals**Contact Layout**

PIN 1	(+)
PIN 2	(NC)/(S2)
PIN 3	(-)
PIN 4	(NO)/(S1)
LED display	LED (green): Power / LED (yellow): (S1) / LED (white): Signal (S2)

General data

Temperature range -20...+80 °C, depending on cable quality

Cables

Cable number	389
No./diameter of wires	12× 0.34 + 2× 0.75 mm ²
C-track properties	5 Mio.
Jacket Color	gray
Material (jacket)	PUR (UL/CSA)
Outer Ø	9.5 mm ±5%
Bend radius (fixed)	5× outer Ø
Bend radius (moving)	10× outer Ø
Temperature range (fixed)	-40...+80 °C
Temperature range (mobile)	-5...+60 °C
Approval (cable)	UL (AWM-Style 20233), CSA

Technical Data

Operating current per contact	max. 2 A
Protection	IP67 inserted and tightened (EN 60529)
Operating voltage	24 V DC
Signal per port	2
Total current	max. 8 A
Housing	Plastic, flame retardant
Locking of ports	Screw thread (M8×1 mm)
Commercial data	
country of origin	CZ
customs tariff number	85444290
EAN	4048879054881
eClass	27143423
Packaging unit	1