

EXACT12, 8XM12, 4 POLE CAP, PLUG. SCREW TERM.

Self wireable, no LED

8-way, 4-pole

without LED, up to 125 V AC/DC

Screw plug-in terminals

Plastic housings with good resistance against chemicals and oils.




 
 
The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)

Illustration



M12-Females 4-pole

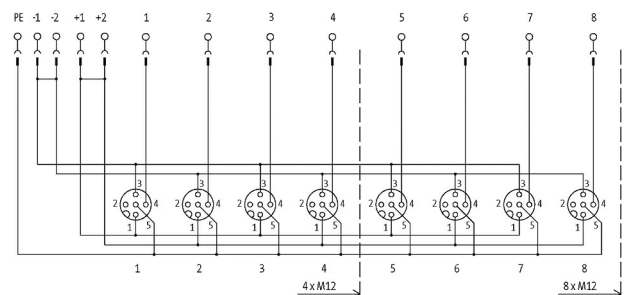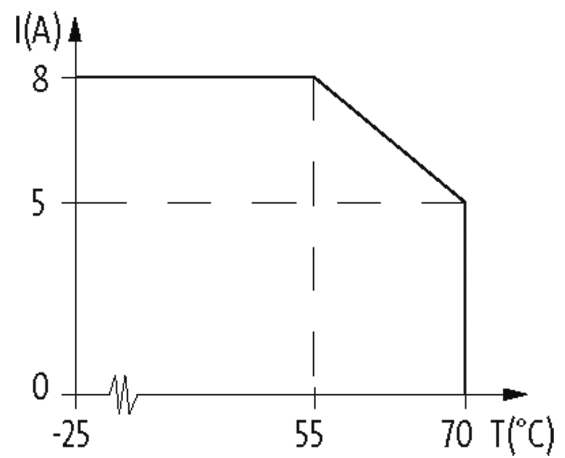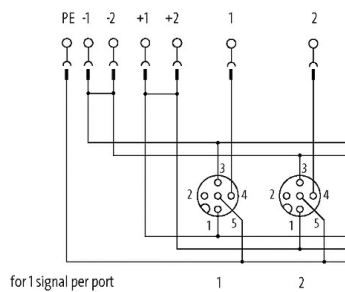

Product may differ from Image

Contact Layout

PIN 1 (+)

PIN 3	(-)
-------	-----

PIN 4	(NO)/(S1)
-------	-----------

PIN 5	(Earth)
-------	---------

General data

Temperature range	-20...+70 °C
-------------------	--------------

Technical Data

Operating voltage	125 V AC/DC
-------------------	-------------

Operating current per contact	max. 4 A
-------------------------------	----------

Total current	max. 8 A
---------------	----------

Connection	Screw plug-in terminals: max. 1.5 mm ² (AWG 16)
------------	--

Protection	IP65/IP67
------------	-----------

Housing	Plastic, flame retardant
---------	--------------------------

Commercial data

country of origin	DE
-------------------	----


customs tariff number	85369010
-----------------------	----------

EAN	4048879054140
-----	---------------

eClass	27143423
--------	----------

Packaging unit	1
----------------	---

Sketch

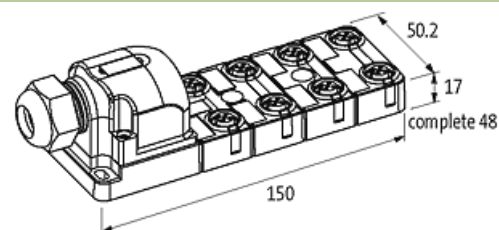

Product may differ from Image