

EXACT12, 8XM12, 5-POLE, CON. M23 19 POLE

Without con. cable

8-way, 5-pole

M23 plug connection

19-pole used


with LED for digital PNP-signals 24 V DC

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.



[Link to Product](#)

Illustration


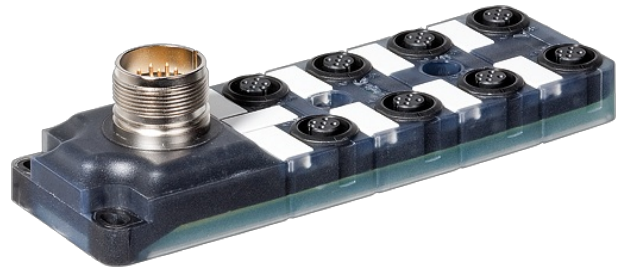


M12-Females 5-pole

M23-Plug 19-pole

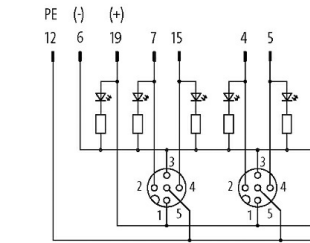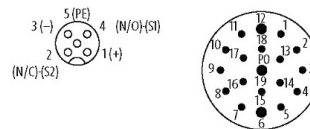


for 2 signals per port

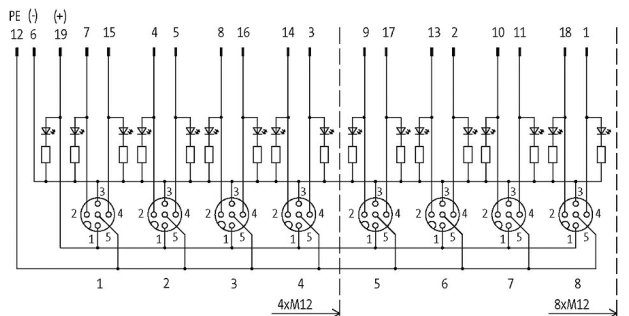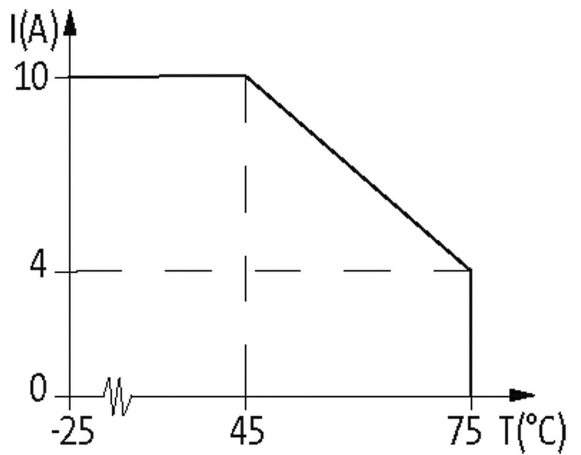

Product may differ from Image

Approvals

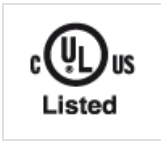

Contact Layout

PIN 1	(+)
PIN 2	(NC)/(S2)
PIN 3	(-)
PIN 4	(NO)/(S1)
PIN 5	(Earth)
LED display	LED (green): Power / LED (yellow): (S1) / LED (white): Signal (S2)

General data

Temperature range	-20...+80 °C
-------------------	--------------


Technical Data

Operating voltage	24 V DC
Operating current per contact	max. 4 A
Total current	max. 8 A
Protection	IP65/IP67
Housing	Plastic, flame retardant

Commercial data

country of origin	DE
customs tariff number	85369010
EAN	4048879053860
eClass	27143423
Packaging unit	1

Sketch

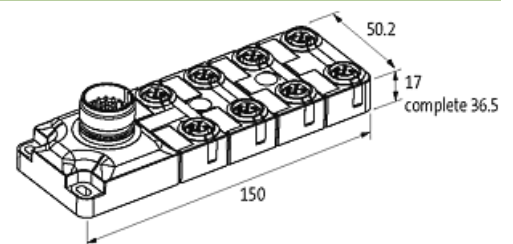

Product may differ from Image