

### **CAP BIG WITH PLUG. SPRING TERM. 21-POLE**

For use with 4-,6-,8-way d-box M12 5-pole

Cap for 4-, 6-, and 8-way distribution box, 5-pole


Spring clamp plug-in terminals

Plastic housings with good resistance against chemicals and oils.



The resistance to aggressive media should be individually tested for your application. Further details on request.

#### [Link to Product](#)

Illustration

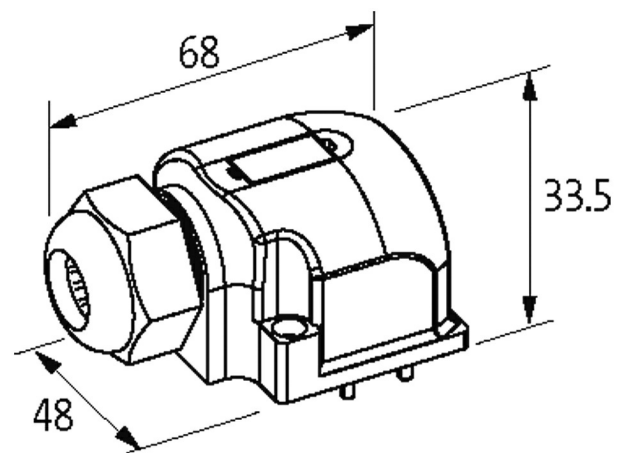

M12-Females 5-pole

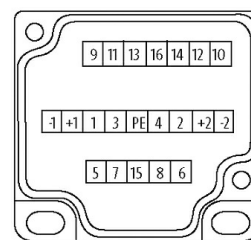 

for 2 signals per port

Product may differ from Image

**General data**

Temperature range -20...+80 °C, depending on cable quality

**Technical Data**

Total current max. 2x 8 A

Connection Spring clamp plug-in terminals: max. 1.5 mm<sup>2</sup> (AWG 16)

Housing Plastic, flame retardant

**Commercial data**

country of origin CZ

customs tariff number	85369010
EAN	4048879300032
eClass	27143423
Packaging unit	1