

EXACT12, 8XM12, 5-POLE, CAP, PLUG. SCREW TERM.

Self wireable, no LED

8-way, 5-pole

without LED, up to 125 V AC/DC

Screw plug-in terminals

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.



Further cable lengths on request.

[Link to Product](#)



Illustration



M12 Females 5-pole

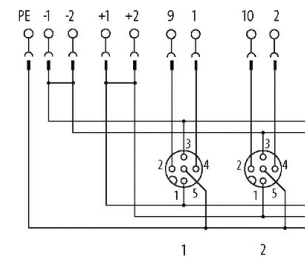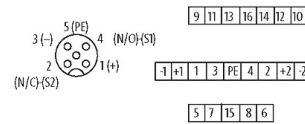

for 2 signals per port

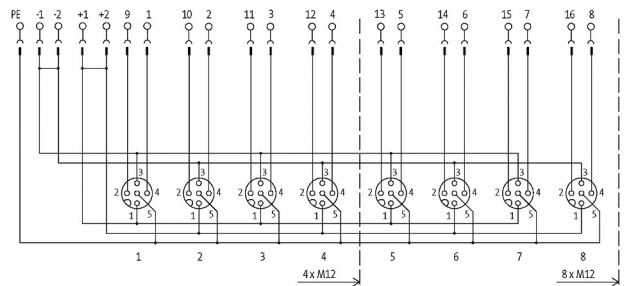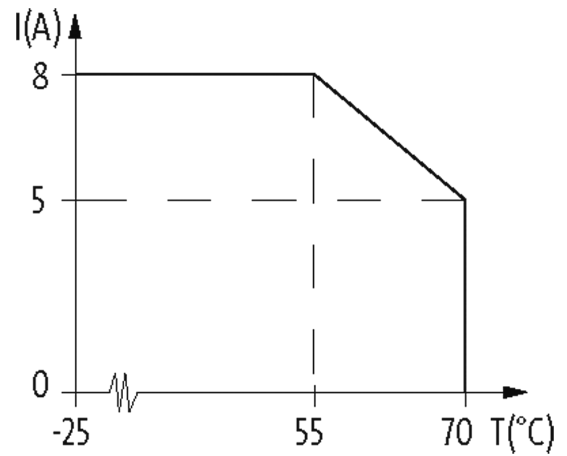

Product may differ from Image

Contact Layout

PIN 1	(+)
PIN 2	(NC)/(S2)

PIN 3	(-)
PIN 4	(NO)/(S1)

General data


Temperature range	-20...+70 °C
-------------------	--------------

Technical Data

Operating voltage	125 V AC/DC
Operating current per contact	max. 4 A
Total current	max. 8 A
Connection	Screw plug-in terminals: max. 1.5 mm ² (AWG 16)
Protection	IP65/IP67
Housing	Plastic, flame retardant

Commercial data

country of origin	DE
customs tariff number	85369010
EAN	4048879053822
eClass	27143423
Packaging unit	1

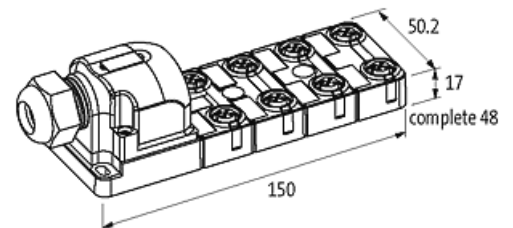Sketch

Product may differ from Image