

**EXACT12, 8XM12, 5 POL.**

Backside spring terminals

5-pole

rear connection


Spring clamp terminals

with LED for digital PNP-signals 24 V DC

Plastic housings with good resistance against chemicals and oils.




The resistance to aggressive media should be individually tested for your application. Further details on request.

flat gasket included

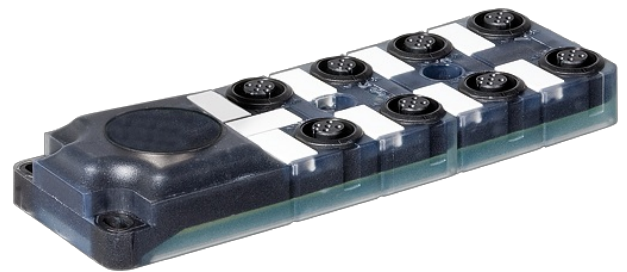
**[Link to Product](#)****Illustration**

M12-Females 5-pole

  Bottom view

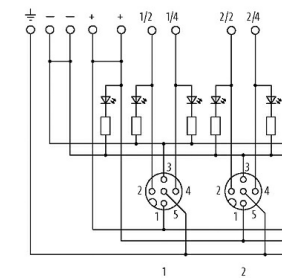


for 2 signals per port

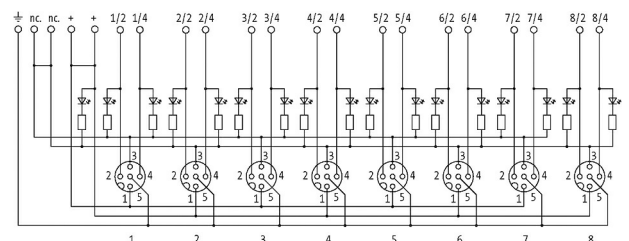

Product may differ from Image

**Approvals**

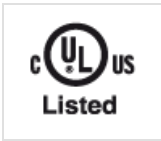

#### Contact Layout

PIN 1	(+)
PIN 2	(NC)/(S2)
PIN 3	(-)
PIN 4	(NO)/(S1)
PIN 5	(Earth)
LED display	LED (green): Power / LED (yellow): (S1) / LED (white): Signal (S2)

#### General data

Temperature range	-20...+70 °C
-------------------	--------------


#### Technical Data

Operating voltage	24 V DC
Operating current per contact	max. 4 A
Total current	max. 2× 8 A
Protection	IP65/IP67
Housing	Plastic, flame retardant

#### Commercial data

country of origin	DE
customs tariff number	85369010
EAN	4048879311823
eClass	27143423
Packaging unit	1

#### Sketch

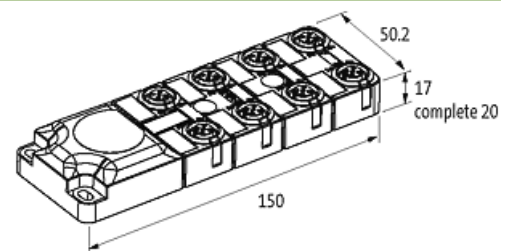

Product may differ from Image