

EXACT12, 8XM12, 5 POL.

Backside plug. spring terminals

5-pole

pluggable rear connection


Spring clamp plug-in terminals

with LED for digital PNP-signals 24 V DC


Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.




flat gasket included

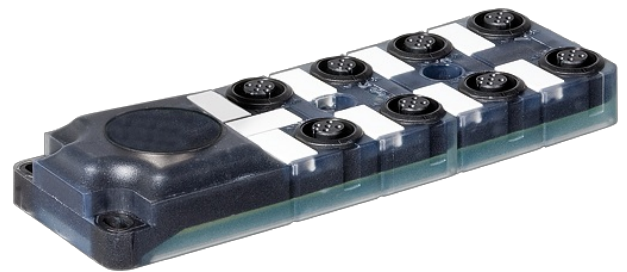[Link to Product](#)**Illustration**

 
M12-Females 5-pole



Bottom view

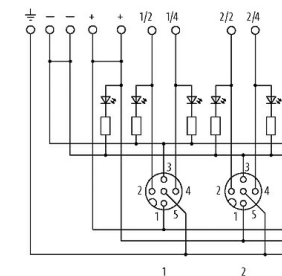  


for 2 signals per port

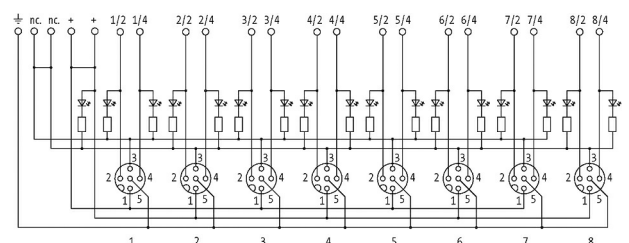

Product may differ from Image

Approvals

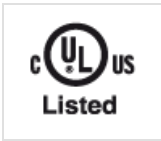

Contact Layout

PIN 1	(+)
PIN 2	(NC)/(S2)
PIN 3	(-)
PIN 4	(NO)/(S1)
PIN 5	(Earth)
LED display	LED (green): Power / LED (yellow): (S1) / LED (white): Signal (S2)

General data

Temperature range	-20...+70 °C
-------------------	--------------


Technical Data

Operating voltage	24 V DC
Operating current per contact	max. 4 A
Total current	max. 2× 8 A
Protection	IP65/IP67
Housing	Plastic, flame retardant

Commercial data

country of origin	DE
customs tariff number	85369010
EAN	4048879311205
eClass	27143423
Packaging unit	1

Sketch

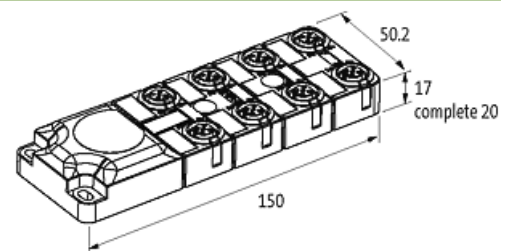

Product may differ from Image