

MEN POWER SUPPLY 1/2-PHASE, SMOOTHED

IN: 230/400+/-15VAC OUT: :24V/10ADC

Current: 10 A

Output rating: 240 W

This power supply units meet the (EN 61000-3-2) standard for harmonic current.

[Link to Product](#)**Illustration**

Product may differ from Image

Approvals**Input**

Input voltage	230/400 ±15 V AC
Input current	1.7 A (230 V AC); 0.97 A (400 V AC)
Input fuse (external)	3.15 AT (230 V AC); 1.6 AT (400 V AC)
Frequency	50...60 Hz

Output

Output voltage	24 V DC (SELV)
Output current (Ta 60/40 °C)	max. 10 A (230 V AC); 12 A (400 V AC)
Ripple	max. 5% eff/rms
Output fuse	20 A (automotive fuse FKS)
Output suppression	LED, VDR and smoothing capacitor



General data

Standards	EN 61558-2-6, EN 62041 category I, EN 55011 B, EN 61000-3-2
Mounting method	Key-hole mounting
Dimensions H×W×D	112.5×120×160 mm
Fixing centers a×b×c	94.5×90×5.8 mm
Temperature range	-20...+60 °C, no condensation

Commercial data

country of origin	CZ
customs tariff number	85044090
EAN	4048879080057
eClass	27049002
Packaging unit	1

Sketch

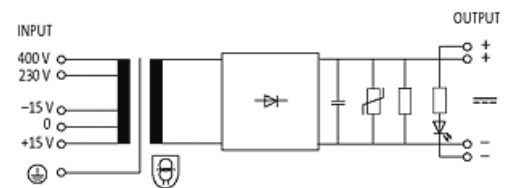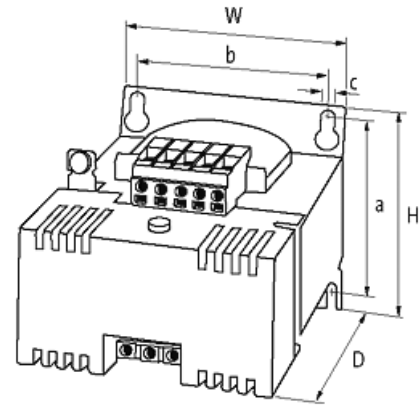

Product may differ from Image