

MEN POWER SUPPLY 1/2-PHASE, SMOOTHED

IN: 230/400±15VAC OUT: :24V/15ADC

Current: 15 A

Output rating: 360 W

This power supply units meet the (EN 61000-3-2) standard for harmonic current.

[Link to Product](#)**Illustration**

Product may differ from Image

Approvals**Input**

Input voltage	230/400 ±15 V AC
Input current	2.8 A (230 V AC); 1.65 A (400 V AC)
Input fuse (external)	4 AT (230 V AC); 2.5 AT (400 V AC)
Frequency	50...60 Hz

Output

Output voltage	24 V DC (SELV)
Output current (Ta 60/40 °C)	max. 15 A (230 V AC); 18 A (400 V AC)
Ripple	max. 5% eff/rms
Output suppression	LED, VDR and smoothing capacitor

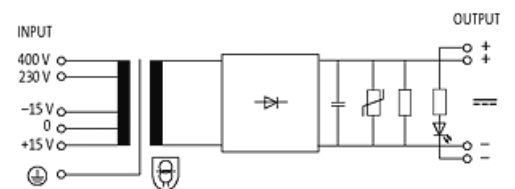
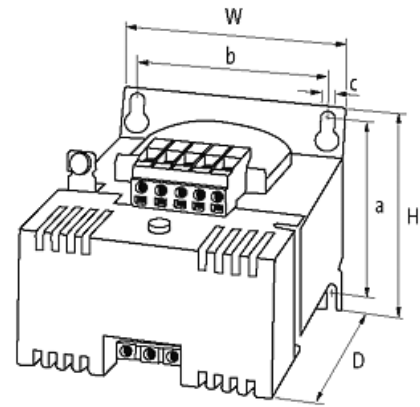
General data

Standards	EN 61558-2-6, EN 62041 category I, EN 55011 B, EN 61000-3-2
Mounting method	Key-hole mounting
Dimensions H×W×D	138.5×135×181.5 mm
Fixing centers a×b×c	126×104×6.5 mm
Temperature range	-20...+60 °C, no condensation

Commercial data

country of origin	CZ
-------------------	----

customs tariff number	85044090
EAN	4048879080040
eClass	27049002
Packaging unit	1

Sketch

Product may differ from Image