

MEN POWER SUPPLY 1/2-PHASE, SMOOTHED

IN: 115/230+/-10VAC OUT: :24V/1ADC

Current: 1 A

Output rating: 24 W

[Link to Product](#)**Illustration**

Product may differ from Image

Approvals**Input**

Input voltage	115/230 V AC \pm 10 V AC
Input current	0.54 A (115 V AC); 0.27 A (230 V AC)
Input fuse (external)	0.8 A (T) (115 V AC); 0.4 A (T) (230 V AC)
Frequency	50..60 Hz

Output

Output voltage	24 V DC (SELV)
Ripple	max. 5% eff/rms
Output current (Ta 60/40 °C)	max. 1 A (115 V AC); 1.5 A (230 V AC)
Output fuse	3 A (automotive fuse FKS)
Output suppression	LED, VDR and smoothing capacitor

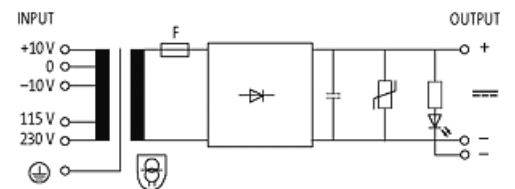
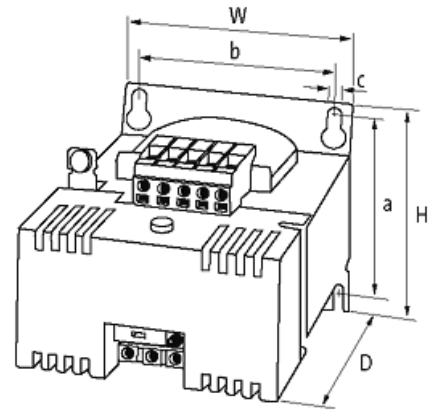
General data

Standards	EN 61558-2-6, EN 62041 category I, EN 55011 B, EN 61000-3-2
Mounting method	Key-hole mounting
Temperature range	-20...+60 °C, no condensation
Dimensions H×W×D	64×78×120 mm
Fixing centers a×b×c	47.5×56×4.8 mm

Commercial data

country of origin	CZ
-------------------	----

customs tariff number	85044090
EAN	4048879079990
eClass	27049002
Packaging unit	1

Sketch

Product may differ from Image