

MEN POWER SUPPLY 1/2-PHASE, SMOOTHED

IN: 115/230+/-10VAC OUT: :24V/2,5ADC

Current: 2.5 A

Output rating: 60 W

without DIN-rail adapter

This power supply units meet the (EN 61000-3-2) standard for harmonic current.

For any mounting position at vertical wall.

[Link to Product](#)**Illustration**

Product may differ from Image

Approvals**Input**

Input voltage	115/230 V AC \pm 10 V AC
Input current	1 A (115 V AC); 0.5 A (230 V AC)
Frequency	50..60 Hz
Input fuse (external)	1.6 AT (115 V AC); 0.8 AT (230 V AC)

Output

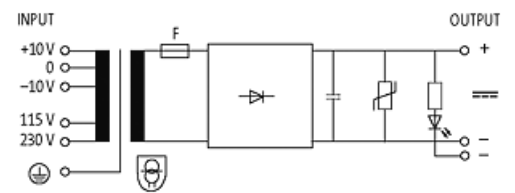
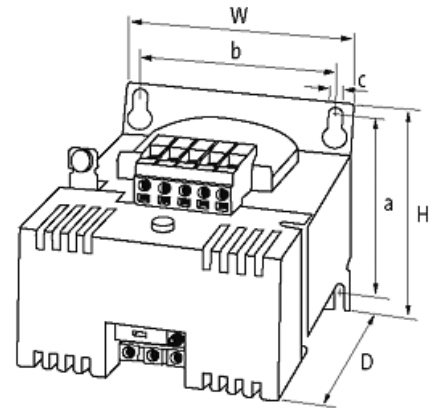
Output voltage	24 V DC (SELV)
Ripple	max. 5% eff/rms
Output current (Ta 60/40 °C)	max. 2.5 A (115 V AC); 3 A (230 V AC)
Output fuse	7.5 A (automotive fuse FKS)
Output suppression	LED, VDR and smoothing capacitor

General data

Standards	EN 61558-2-6, EN 62041 category I, EN 55011 B, EN 61000-3-2
Mounting method	Key-hole mounting
Temperature range	-20...+60 °C, no condensation
Dimensions H×W×D	83×84×124 mm
Fixing centers a×b×c	65.5×64×4.8 mm

Commercial data

country of origin	CZ
customs tariff number	85044090
EAN	4048879079983
eClass	27049002
Packaging unit	1

Sketch

Product may differ from Image