

MEN POWER SUPPLY 1/2-PHASE, SMOOTHED

IN: 115/230+/-10VAC OUT: :24V/10ADC

Current: 10 A

Output rating: 240 W

This power supply units meet the (EN 61000-3-2) standard for harmonic current.
For any mounting position at vertical wall.

[Link to Product](#)**Illustration**

Product may differ from Image

Approvals**Input**

Input voltage	115/230 V AC \pm 10 V AC
Input current	3.7 A (115 V AC); 1.85 A (230 V AC)
Input fuse (external)	5 A (T) (115 V AC); 2.5 A (T) (230 V AC)
Frequency	50...60 Hz

Output

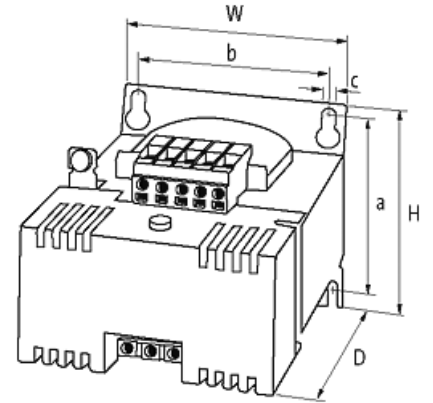
Output voltage	24 V DC (SELV)
Output current (Ta 60/40 °C)	max. 10 A (115 V AC); 12 A (230 V AC)
Ripple	max. 5% eff/rms
Output fuse	20 A (automotive fuse FKS)
Output suppression	LED, VDR and smoothing capacitor

General data

Standards	EN 61558-2-6, EN 62041 category I, EN 55011 B, EN 61000-3-2
Mounting method	Key-hole mounting
Dimensions HxWxD	112.5x120x160 mm
Fixing centers axbxc	94.5x90x5.8 mm
Temperature range	-20...+60 °C, no condensation

Commercial data

country of origin	CZ
customs tariff number	85044090
EAN	4048879079952
eClass	27049002
Packaging unit	1

Sketch

Product may differ from Image