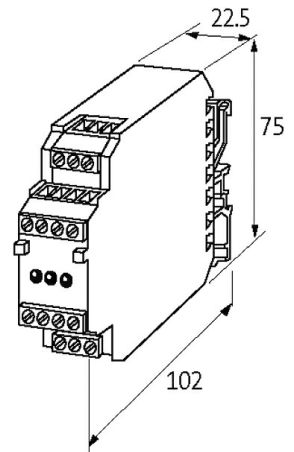


**MKN POWER SUPPLY 1-PHASE, LINEAR REGULATED**

IN: 230VAC OUT: 10V/0,08ADC

INPUT: 230 V AC  
 OUTPUT: 10 V DC  
 Current: 80 mA

This power supply units meet the (EN 61000-3-2) standard for harmonic current.

[Link to Product](#)**Illustration**

Product may differ from Image

**Input**

Input current	approx. 20 mA
Input fuse (external)	63 mA (T)
Frequency	50...60 Hz
Input voltage	207...253 V AC

**Output**

Output current	max. 80 mA
Ripple	max. 10 mV ss/pp
Output suppression	VDR and smoothing capacitor
Unit protection	short-circuit and overload protected

