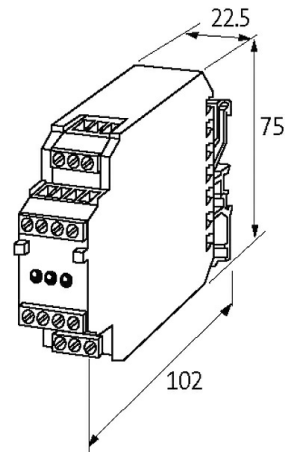


MKN POWER SUPPLY 1-PHASE, LINEAR REGULATED

IN: 230VAC OUT: 2x10V/0,1ADC

INPUT: 230 V AC
OUTPUT: +-10 V DC
Current: 2x 50 mA

This power supply units meet the (EN 61000-3-2) standard for harmonic current.

[Link to Product](#)**Illustration**

Product may differ from Image

Input

Input voltage	207...253 V AC
Input current	approx. 20 mA
Input fuse (external)	63 mA (T)
Frequency	50...60 Hz

Output

Output current	max. 2x 50 mA
Output suppression	LED, VDR and smoothing capacitor
Ripple	max. 10 mV ss/pp
Unit protection	short-circuit and overload protected

LED display LED (green): in operation

General data

Standards EN 61558-2-6, EN 62041 category II, EN 55011 B, EN 61000-3-2

Mounting method DIN-rail mountable TH35 or G32 (EN 60715)

Temperature range 0...+60 °C, no condensation

Commercial data

country of origin CZ

customs tariff number 85044090

EAN 4048879079648

eClass 27049002

Packaging unit 1