

MKN POWER SUPPLY 1-PHASE, LINEAR REGULATED

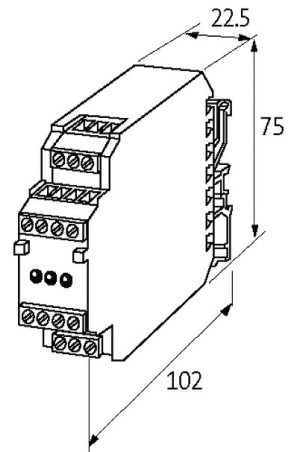
IN: 230VAC OUT: 9,5-15V/0,1ADC

INPUT: 230 V AC

OUTPUT: 9.5...15 V DC

Current: 100 mA

This power supply units meet the (EN 61000-3-2) standard for harmonic current.

[Link to Product](#)**Illustration**

Product may differ from Image

Input

Input voltage	207...253 V AC
Input current	approx. 30 mA
Input fuse (external)	63 mA (T)
Frequency	50...60 Hz

Output

Output current	max. 100 mA
Ripple	max. 10 mV ss/pp
Output suppression	VDR and smoothing capacitor
Unit protection	short-circuit and overload protected

LED display LED (green): in operation

General data

Standards EN 61558-2-6, EN 62041 category II, EN 55011 B, EN 61000-3-2

Mounting method DIN-rail mountable TH35 or G32 (EN 60715)

Temperature range 0...+60 °C, no condensation

Commercial data

country of origin CZ

customs tariff number 85044090

EAN 4048879079617

eClass 27049002

Packaging unit 1