

**MPL POWER SUPPLY 3-PHASE, SMOOTHED**

IN: 400VAC+/- 5% OUT: 24V/50ADC

Current: 50 A

Output rating: 1200 W

[Link to Product](#)**Illustration**

Product may differ from Image

**Approvals****Input**

Input voltage	3 x 400 V AC $\pm$ 5%
Input current	2.5 A (3 x 400 V AC)
Input fuse (external)	4 A (T)
Frequency	50...60 Hz

**Output**

Output voltage	24 V DC (SELV)
Output current	max. 50 A
Ripple	max. 2% eff/rms
Output fuse external	50 A (T)
Output suppression	LED, VDR and smoothing capacitor

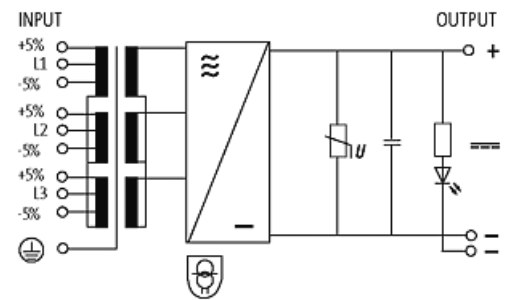
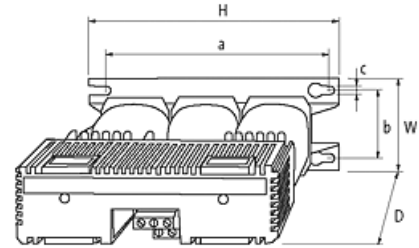
**General data**

Standards	EN 61558-2-6, EN 62041 category I, EN 55011 B, EN 61000-3-2
Temperature range	-20...+55 °C, for any mounting position at vertical wall, no condensation
Mounting method	Key-hole mounting
Efficiency	79%
Dimensions HxWxD	280x134x313 mm
Fixing centers axbxc	256.5x108x11 mm

**Commercial data**

country of origin	CZ
customs tariff number	85044090

EAN	4048879079174
eClass	27049002
Packaging unit	1

**Sketch**

Product may differ from Image