

MPL POWER SUPPLY 3-PHASE, SMOOTHED

IN: 400VAC+/- 5% OUT: 24V/60ADC

Current: 60 A

Output rating: 1440 W

[Link to Product](#)**Illustration**

Product may differ from Image

Approvals**Input**

Input voltage	3 × 400 V AC ±5%
Input current	3.1 A (3 × 400 V AC)
Input fuse (external)	4 A (T)
Frequency	50...60 Hz

Output

Output voltage	24 V DC (SELV)
Output current	max. 60 A
Ripple	max. 2% eff/rms
Output fuse external	60 A (T)
Output suppression	LED, VDR and smoothing capacitor

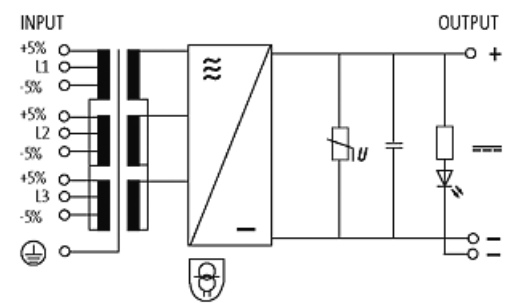
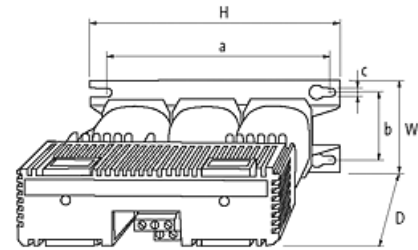
General data

Standards	EN 61558-2-6, EN 62041 category I, EN 55011 B, EN 61000-3-2
Temperature range	-20...+55 °C, for any mounting position at vertical wall, no condensation
Mounting method	Key-hole mounting
Efficiency	78%
Dimensions H×W×D	280×154×313 mm
Fixing centers a×b×c	256.5×128×11 mm

Commercial data

country of origin	CZ
customs tariff number	85044090

EAN	4048879079167
eClass	27049002
Packaging unit	1

Sketch

Product may differ from Image