

MET 1-PHASE CONTROL AND ISOLATION TRANSFORMER

P: 3000VA IN: 230VAC+/- 5% OUT: 230VAC

Single-phase - Control and Isolation Transformers
3000 VA
Isolation class T 40/B

[Link to Product](#)**Illustration**

Product may differ from Image

Approvals**Input**

| | |
|-----------------------|--------------------|
| Input voltage | 230 V AC \pm 5% |
| Frequency | 50...60 Hz |
| Short-circuit current | 623.9 A (230 V AC) |
| Input current | 13.6 A (230 V AC) |
| Inrush current | 209.9 A (230 V AC) |

Output

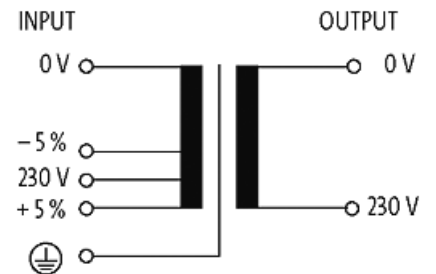
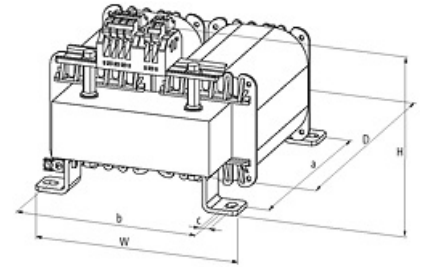
| | |
|----------------|----------|
| Output voltage | 230 V AC |
| Output rating | 3000 VA |

General data

| | |
|--------------------------|---|
| Standards | EN 61558-1, EN 61558-2-4, EN 62041 category 0 |
| Test isolation voltage | 4 kV (prim./sec.) |
| Dimensions H×W×D | 195×198×250 mm |
| Fixing centers a×b×c | 200×174×9 mm |
| Drill hole \varnothing | 9×14 mm |
| Mounting method | Long-hole mounting |
| Temperature range | -20...+40 °C (storage temperature -40...+80 °C) |

Commercial data

| | |
|-----------------------|---------------|
| country of origin | CZ |
| customs tariff number | 85043200 |
| EAN | 4048879078818 |
| eClass | 27031302 |
| Packaging unit | 1 |

Sketch

Product may differ from Image