

MET 1-PHASE CONTROL AND ISOLATION TRANSFORMER

P: 4000VA IN: 400VAC+/- 5% OUT: 230VAC

Single-phase - Control and Isolation Transformers
4000 VA
Isolation class T 40/B

[Link to Product](#)**Illustration**

Product may differ from Image

Approvals**Input**

Input voltage	400 V AC \pm 5%
Input current	10.3 A (400 V AC)
Inrush current	357 A (400 V AC)
Short-circuit current	696 A (400 V AC)
Frequency	50...60 Hz

Output

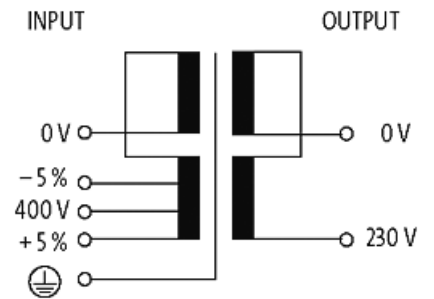
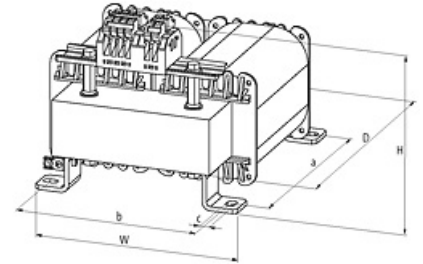
Output voltage	230 V AC
Output rating	4000 VA

General data

Test isolation voltage	4 kV (prim./sec.)
Standards	EN 61558-1, EN 61558-2-4, EN 62041 category 0
Drill hole \varnothing	9x14 mm
Fixing centers a x b x c	200x174x9 mm
Mounting method	Long-hole mounting
Dimensions H x W x D	206x198x250 mm
Temperature range	-20...+40 °C (storage temperature -40...+80 °C)

Commercial data

country of origin	CZ
customs tariff number	85043200
EAN	4048879078788
eClass	27031302
Packaging unit	1

Sketch

Product may differ from Image