

MET 1-PHASE CONTROL AND ISOLATION TRANSFORMER

P: 5000VA IN: 230VAC+/- 5% OUT: 230VAC

Single-phase - Control and Isolation Transformers
5000 VA
Isolation class T 40/B

[Link to Product](#)**Illustration**

Product may differ from Image

Approvals**Input**

Input voltage	230 V AC \pm 5%
Frequency	50...60 Hz
Short-circuit current	1257 A (230 V AC)
Input current	22.6 A (230 V AC)
Inrush current	562 A (230 V AC)

Output

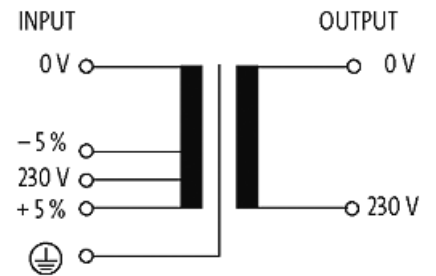
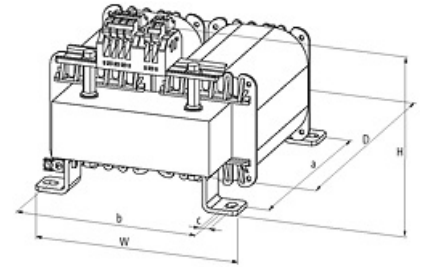
Output voltage	230 V AC
Output rating	5000 VA

General data

Standards	EN 61558-1, EN 61558-2-4, EN 62041 category 0
Test isolation voltage	4 kV (prim./sec.)
Dimensions H×W×D	225×198×250 mm
Fixing centers a×b×c	200×174×9 mm
Drill hole \varnothing	9×14 mm
Mounting method	Long-hole mounting
Temperature range	-20...+40 °C (storage temperature -40...+80 °C)

Commercial data

country of origin	CZ
customs tariff number	85043200
EAN	4048879078771
eClass	27031302
Packaging unit	1

Sketch

Product may differ from Image