

MST 1-PHASE CONTROL AND ISOLATION TRANSFORMER

P: 800VA IN: 208...550VAC OUT: 2x115VAC

Single-phase - Control and Isolation Transformers
 800 VA
 Isolation class T 40/B
 Other voltages on request.

[Link to Product](#)**Illustration**

Product may differ from Image

Approvals**Input**

Input voltage	208, 230, 380, 400, 420, 440, 460, 480, 500, 525, 550 V AC
Input current	4.2 A (208 V AC); 1.61 A (550 V AC)
Inrush current	96 A (208 V AC); 36 A (550 V AC)
Short-circuit current	123 A (208 V AC); 47 A (550 V AC)
Frequency	50...60 Hz

Output

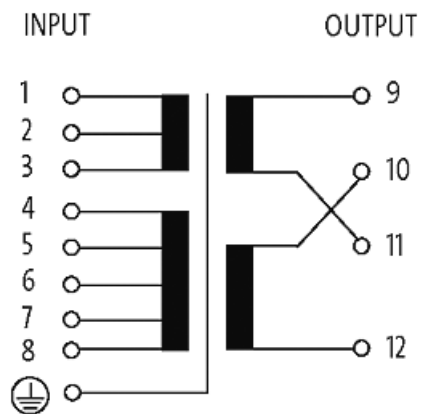
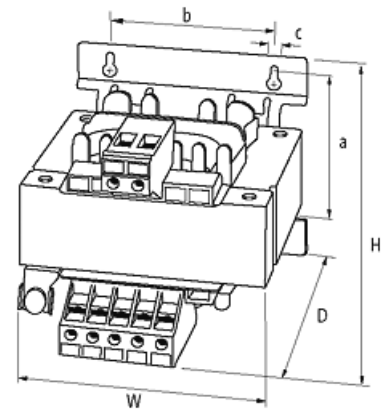
Output voltage	1 × 230, 1 × 115, 2 × 115 V AC
Output rating	800 VA

General data

Standards	EN 61558-1, EN 61558-2-4, EN 62041 category 0
Test isolation voltage	4 kV (prim./sec.)
Mounting method	Key-hole mounting
Dimensions H×W×D	156×150×150 mm
Fixing centers a×b×c	134×122×7 mm
Drill hole Ø	7×11 mm
Temperature range	-20...+40 °C (storage temperature -20...+80 °C)

Commercial data

country of origin	CZ
customs tariff number	85043180
EAN	4048879078733
eClass	27031302
Packaging unit	1

Sketch

Product may differ from Image