

Mico Pro electronic circuit protection, 1 channel

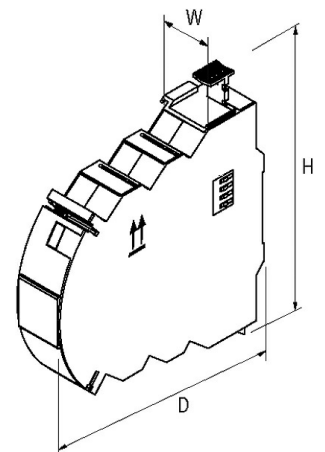
IN: 24 V DC OUT: 24 V DC / 1-2-3-4-5-6-7-8-9-10A

Mico Pro® flex 1.10

1 channel

1, 2, 3, 4, 5, 6, 7, 8, 9, 10 A

Build your own Mico Pro® online:

<https://micopro.murrelektronik.com>**[Link to Product](#)****Illustration**

Product may differ from Image

Approvals**Input**

Operating voltage 12 V DC; 24 V DC (9...30 V DC)

Total current max. 40 A

Output

Current adjustment	1, 2, 3, 4, 5, 6, 7, 8, 9, 10 A
--------------------	---------------------------------

No. of channels	1
-----------------	---

Inrush capacity	max. 30 mF
-----------------	------------

Tolerance	0...+20%
-----------	----------

Parallel usage/serial usage	-/Selectivity in 2 levels
-----------------------------	---------------------------

Control inputs

Input voltage (ON)	9...30 V DC
--------------------	-------------

Impulse length (ON)	"high" 120 ms
---------------------	---------------

Input voltage (CTRL)	9...30 V DC
----------------------	-------------

Impulse length (CTRL)	OFF "high" 40/400 ms, ON "high" 20/200 ms
-----------------------	---

Control outputs

Group alarm output	via power module
--------------------	------------------

Early warning (90%)	like operating voltage - max. 20 mA, via power module
---------------------	---

General data

Protection	IP20
------------	------

Bridging concept	Bridge set (max. 40 A)
------------------	------------------------

Mounting method	DIN-rail mountable TH35 (EN 60715)
-----------------	------------------------------------

Temperature range	-25...+55 °C (storage temperature -40...+80 °C)
-------------------	---

Dimensions H×W×D	130×8×114 mm
------------------	--------------

Connections (IN)

Connection	Bridge system
------------	---------------

Connections (OUT)

Connection	Push-In spring clamp terminals
------------	--------------------------------

Cross section (rigid)	0.2...2.5 mm ² (AWG 24...14)
-----------------------	---

Cross section (flex)	0.2...4 mm ² (AWG 24...12)
----------------------	---------------------------------------

Commercial data

country of origin	CZ
-------------------	----

customs tariff number	85363010
-----------------------	----------

EAN	4048879552707
-----	---------------

eClass	27141901
--------	----------

Packaging unit	1
----------------	---