



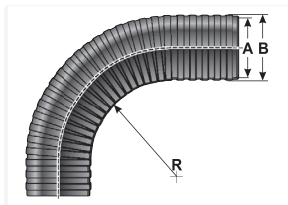

Type EW-PA-LS

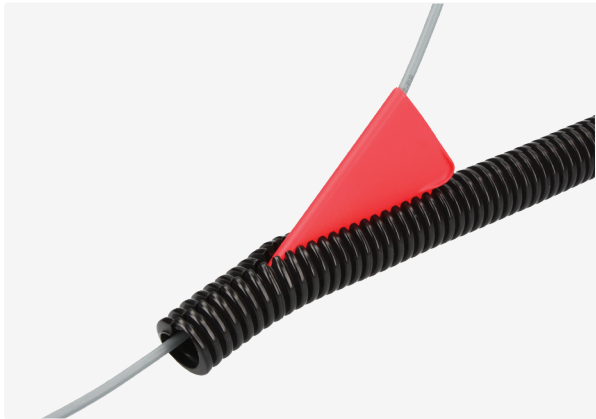

Product information

- simple, lightweight version - for the installation of pre-assembled cables
- flexible conduit for simple dynamic applications
- medium mechanical load
- resource-saving through recycled material
- for mechanical engineering and chemical plants

Color: Black
PU m: 50

Information, conformities and approvals



Article	Order No.	A Ø mm	B Ø mm	R stat. mm	Weight kg/100m
EW-PA-LS-06	83163850	6.6	10	21	2.2
EW-PA-LS-M10/P7	83163851	8.5	11.4	24	2.5
EW-PA-LS-M12/P9	83163852	9.8	13	26	2.8
EW-PA-LS-M16/P11	83163854	12.3	15.8	38	3.8
EW-PA-LS-M20/P16	83163856	15.8	21	55	5.8
EW-PA-LS-M25/P21	83980092	22.5	28.5	59	9.0



Type EW-PA-LS

Material properties



mod. polyamide PA 6



Flexural fatigue strength >24000 ~
According to IEC EN 61386 M20/P16

Thermal properties



Temperature / temperature range -40 °C – 120 °C
short termshort term: 160 °C

Fire properties



Fire classification acc. to
UL94: HB

Chemical resistance



Resistant to: Alcohol, Mi-
neral oils, Greases, Fuels

Technical information



Halogen-free

Conformity



RoHS (EC Directive
2011/65/EU)

General information



Made in Germany