


Type EVK

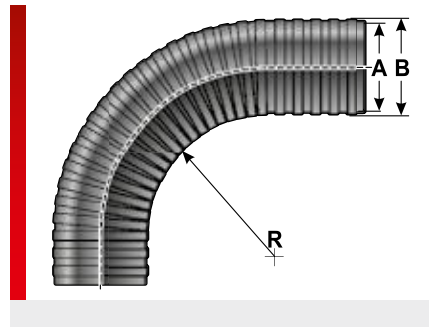

PRODUCT INFORMATION

The EVK cable protection conduits are made of high-quality soft PVC with approx. 30% nitrile rubber. The integrated support coil made of rigid PVC gives the conduit a high level of dimensional stability. This makes the conduits ideal for static applications involving high mechanical loads.

The EVK cable protection conduits are used mainly to protect electrical cables in machine construction and mechanical engineering and feature the following advantages:

- Excellent dimensional stability
- Hard-wearing and kink-resistant
- Weather-resistant and hard-wearing

SPECIFICATIONS

- 5 – 140 °F
- Polyvinyl chloride (PVC)
- Acc. to UL94 V2 self-extinguishing
- In conformity with IEC EN 61386
Crush resistance: > 650 N



| Type | Order No. | Color | A Ø inch | B Ø inch | R stat. inch | Weight lbs/100ft | Pack ft. |
|------------------------|-----------|-------|-------------|-------------|-----------------|---------------------|-------------|
| EVK 07/E | 83301252 | Black | 0.39 | 0.54 | 0.39 | 6.38 | 164.04 |
| EVK 07 | 83301210 | Gray | 0.35 | 0.53 | 0.35 | 5.71 | 164.04 |
| EVK 07/E | 83301212 | Gray | 0.39 | 0.54 | 0.39 | 6.38 | 82.02 |
| EVK 09/E | 83301216 | Gray | 0.51 | 0.68 | 0.51 | 8.06 | 164.04 |
| EVK 09 | 83301214 | Gray | 0.55 | 0.74 | 0.55 | 9.41 | 164.04 |
| EVK 11/E ¹⁾ | 83301220 | Gray | 0.59 | 0.77 | 0.59 | 10.08 | 164.04 |
| EVK 11 | 83301218 | Gray | 0.63 | 0.81 | 0.63 | 10.08 | 164.04 |
| EVK 13 ¹⁾ | 83301222 | Gray | 0.75 | 0.94 | 0.75 | 11.42 | 164.04 |
| EVK 16 | 83301224 | Gray | 0.79 | 0.97 | 0.79 | 14.11 | 164.04 |
| EVK 21/E ¹⁾ | 83301228 | Gray | 0.87 | 1.05 | 0.87 | 15.46 | 164.04 |
| EVK 21 | 83301226 | Gray | 1.06 | 1.27 | 1.06 | 16.8 | 164.04 |
| EVK 21 without print | 83980141 | Gray | 1.06 | 1.27 | 1.06 | 16.8 | 164.04 |
| EVK 29/E | 83301232 | Gray | 1.18 | 1.41 | 1.18 | 20.16 | 82.02 |
| EVK 29 | 83301230 | Gray | 1.38 | 1.59 | 1.38 | 26.21 | 82.02 |
| EVK 36/E | 83301236 | Gray | 1.50 | 1.72 | 1.50 | 29.57 | 82.02 |
| EVK 36 ¹⁾ | 83301234 | Gray | 1.77 | 2.02 | 1.77 | 34.27 | 82.02 |
| EVK 42 ¹⁾ | 83301238 | Gray | 1.97 | 2.23 | 1.97 | 39.65 | 82.02 |
| EVK 48 ¹⁾ | 83301240 | Gray | 2.17 | 2.45 | 2.17 | 43.68 | 82.02 |

¹⁾ No stock goods, delivery time and minimum order quantities upon request