

# Snap Action, Subminiature




## Features

- Actuator: Hinge Roller Lever



## S45

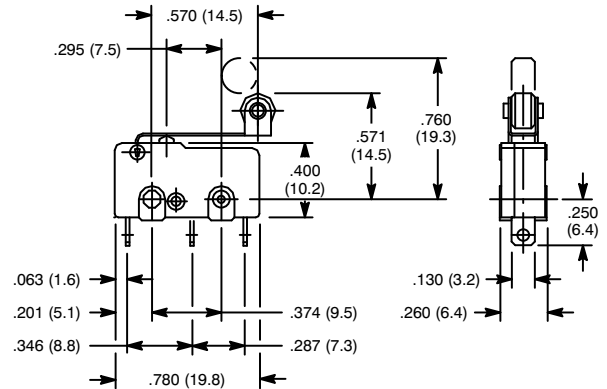

NTE Type No.	Circuitry	Max. Free Position	Min. Over Travel	Max. Operating Force	Max. Differential	Diag No.
54-416	SPDT	0.76"	0.039"	50g	0.039"	S45

## Specifications

- Current Rating:** 10.1A 125/250VAC, 0.4A 125VDC, 0.2A 250VDC
- Contact Resistance:** 30 Milliohms (max.) initial
- Insulation Resistance:** 100 Megohms at 500VDC
- Dielectric Strength:** 1000VAC (50/60Hz for 1 minute)
- Temperature Rating:** -13°F to +185°F (-25°C to +85°C) with no icing
- Electrical Life:** 50,000 cycles min. (under rated load)
- Mechanical Life:** 10,000,000 cycles min.
- Terminal Type:** Solder Terminals