


Four Pole Distribution Blocks

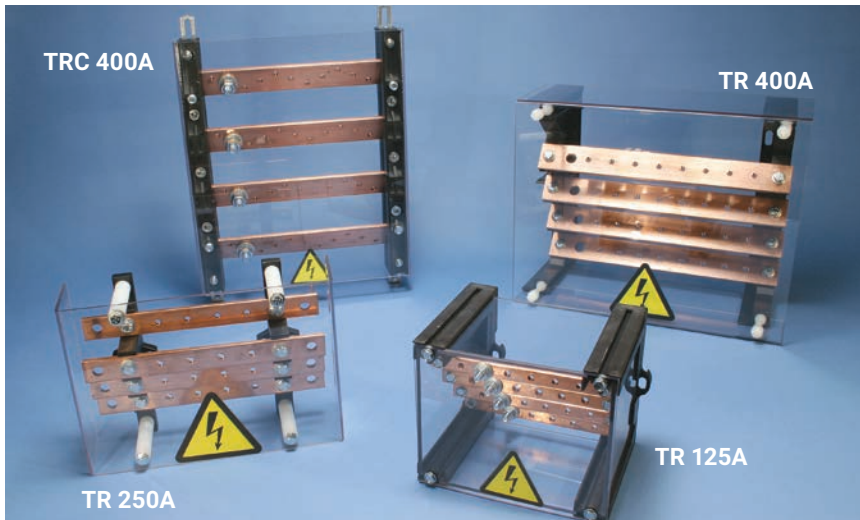


- A complete range from 125 A to 630 A
- Transparent protection cover
- Large accessibility for wiring
- Pre-assembled
- Self Extinguishing: UL94 V-0
- RoHS Compliant

IEC 61439.1

TR 125A

Threaded bars
12 x 4 - I = 125 A

- Easy clip in fixing for DIN rail or sheet steel
- Protection screen on 5 sides
- Equipped with a current input plug M6
- 5 outlets M5 per phase

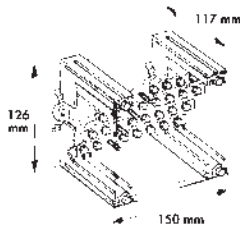


- Icw KA rms 1s: 20
- IPk KÄ: 40
- Ui = 1000V

Part No.	Description		
563150	TR 125A	1	0,684

TRS 160A

Threaded bars
15 x 5 - I = 160 A

- Easy fixing for DIN rail G or sheet steel
- Incomers right or left Ø 8 mm
- 6 outlets M6 per phase

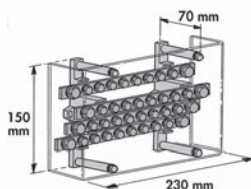


- Icw KA rms 1s: 17
- IPk KÄ: 34
- Ui = 630V

Part No.	Description		
563160	TRS 160A	1	1,15

TR 250A

Threaded bars
20 x 5 - I = 250 A

- Easy fixing for DIN rail G or sheet steel
- Incomers right or left Ø 8 mm
- 4 outlets M6 per phase

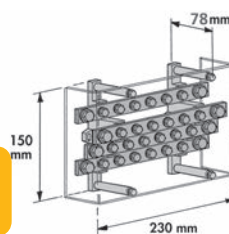


- Icw KA rms 1s: 17
- IPk KÄ: 34
- Ui = 630V

Part No.	Description		
563170	TR 250A	1	1,30

TR 400A

Threaded bars
32 x 5 - I = 400 A

- Easy fixing for DIN rail or sheet steel
- 1 incomer Ø 10 mm
- 8 outlets M6 per phase

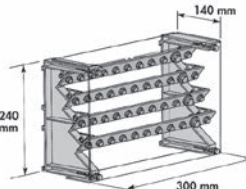


- Icw KA rms 1s: 21
- IPk KÄ: 44
- Ui = 1000V

Part No.	Description		
562010	TR 400A	1	2,83

TRC 400A

Threaded bars
32 x 5 in W - I = 400 A

- Easy connections due to inclined bars
- Equipped with a current input plug M10
- 10 outlets M6 per phase

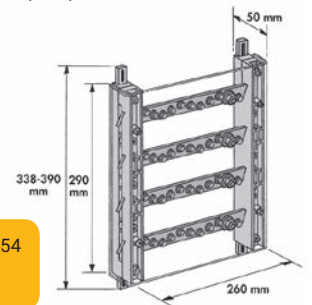


- Icw KA rms 1s: 54
- IPk KÄ: 118
- Ui = 1000V

Part No.	Description		
563180	TRC 400A	1	2,65

TRC 630A

Threaded bars
30 x 10 - I = 630 A

- Incomers Ø 10 mm
- 8 outlets M8 per phase

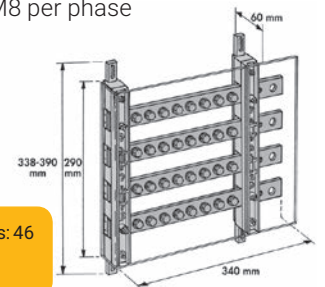

- Icw KA rms 1s: 46
- IPk KÄ: 96
- Ui = 1000V

Part No.	Description		
563190	TRC 630A	1	4,80