
 
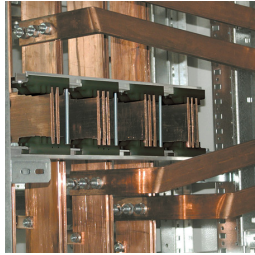


CABS Module Kit with Neutral – CABS3-10TN-MOD (549360)



- Modules provide flexibility to select distance between phases and supports
- Installs quickly and easily
- Halogen free insulators
- RoHS compliant

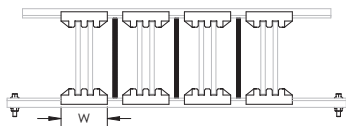

Part Number	CABS3-10TN-MOD
Article Number	549360
Material	Steel Glass Fibre Reinforced Polyamide
Finish	Electrogalvanized
Typical Application Current Rating	400 – 4,500 A
Max Working Voltage, IEC (Ui)	1,000 VAC 1,500 VDC
Working Temperature	-40 to 266 °F
Complies With	IEC® 60439.1 IEC® 61439.1 IEC® 60695-2-11 (Glow Wire Test 960 °C)
Flammability Rating	UL® 94V-0
Busbars per Phase	1 – 3
Busbar Width	1.18" – 4.72"
Busbar Thickness	0.39"
Depth [D]	1.54"
Width [W]	3.94"
Unit Weight	1.28 lb
Certifications	CE EAC 8546901000 (Russian Federation) IEC 61439-1 Busbar Supports RoHS

Part Number	CABS3-10TN-MOD
Standard Packaging Quantity	1 pc
UPC	78285687573
EAN-13	3479775493602

CABS modules must be installed on CABS-APP Aluminium Profile.

IEC is a registered trademark of the International Electrotechnical Commission. UL, UR, cUL, cUR, cULus and cURus are registered certification marks of UL LLC.

© 2019 nVent All rights reserved
nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.
All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.