



# Compact Busbar Support with Neutral Circuit – CBS-B2-5TN (551151)

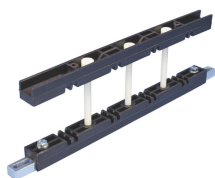

- Compact design fits in 400 mm (15 3/4") deep panels
- Includes mounting holes for direct fixing of protection screen
- Installs quickly and easily
- Halogen free
- RoHS compliant

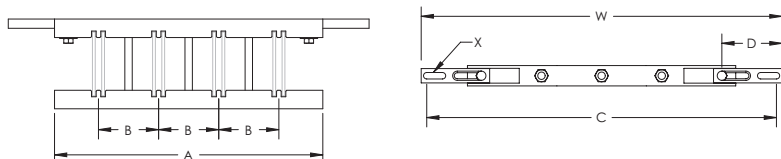

Part Number	CBS-B2-5TN
Article Number	551151
Material	Aluminum Glass Fibre Reinforced Polyamide
Max Working Voltage, IEC (Ui)	1,000 VAC 1,500 VDC
Typical Application Current Rating	250 – 1,600 A
Working Temperature	-40 to 266 °F
Complies With	IEC® 60439.1 IEC® 61439.1 IEC® 60695-2-11 (Glow Wire Test 960 °C)
Flammability Rating	UL® 94V-0
Busbar Width	0.98" – 3.15"
Busbars per Phase	1 – 2
Busbar Thickness	0.2"
Width (W)	13.31" – 15.35"
A	11.42"
B	2.56"
C	12.80" – 14.84"
D	2.56"
X	0.26" x 0.91"
Unit Weight	0.44 lb
Certifications	CE EAC 8546901000 (Russian Federation) IEC 61439-1 Busbar Supports RoHS

Part Number	CBS-B2-5TN
Standard Packaging Quantity	1 pc
UPC	78285687618
EAN-13	3479775511511

IEC is a registered trademark of the International Electrotechnical Commission. UL, UR, cUL, cUR, cULus and cURus are registered certification marks of UL LLC.

© 2019 nVent All rights reserved  
nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.  
All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.

