


FBSS Flat Busbar Support – FBSS32X5 (551190)



- Supports busbars at an angle for easy connections
- Includes mounting holes for direct fixing of protection screen
- Adjustable arms for easy mounting
- Three phase with neutral circuit
- Halogen free

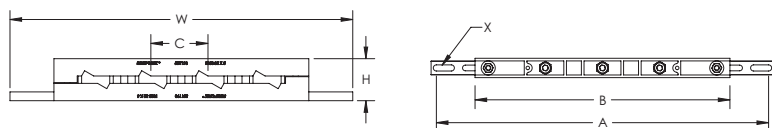

Part Number	FBSS32X5
Article Number	551190
Material	Steel Glass Fibre Reinforced Polyamide Aluminum
Max Working Voltage, IEC (Ui)	1,000 VAC 1,500 VDC
Working Temperature	-40 to 266 °F
Typical Application Current Rating	400 A
Flammability Rating	UL® 94V-0
Busbar Width	1.26"
Busbar Thickness	0.2"
Complies With	IEC® 60695-2-11 (Glow Wire Test 960 °C)
Height (H)	1.85"
Width (W)	13.31" – 15.35"
A	12.80" – 14.84"
B	11.42"
C	2.56"
X	0.26" x 0.91"
Unit Weight	0.7 lb
Certifications	CE EAC 8546901000 (Russian Federation) IEC 61439-1 Busbar Supports RoHS

Part Number	FBSS32X5
Standard Packaging Quantity	2 pc
UPC	78285687619
EAN-13	3479775511900

IEC is a registered trademark of the International Electrotechnical Commission. UL, UR, cUL, cUR, cULus and cURus are registered certification marks of UL LLC.

© 2019 nVent All rights reserved
nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.
All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.