


BS-125A Four Pole Insulating Support – BS-125A (551311)



- Create custom four pole distribution blocks for an electrical distribution system
- Protection screen can be attached directly to the support
- Includes screws to mount threaded copper busbars
- Clips on to DIN rail using DR-CLIP or mounts with screws
- Halogen free
- RoHS compliant

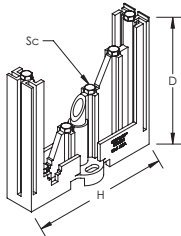

Part Number	BS-125A
Article Number	551311
Material	Steel Glass Fibre Reinforced Polyamide
Finish	Electrogalvanized
Max Working Voltage, IEC (Ui)	1,000 VAC 1,500 VDC
Working Temperature	-40 to 130 °F
Typical Application Current Rating	125 - 160 A
Complies With	IEC® 60439.1 IEC® 61439.1 IEC® 60695-2-11 (Glow Wire Test 960 °C)
Flammability Rating	UL® 94V-0
Busbar Width	0.47" - 0.59"
Busbar Thickness	0.16" - 0.20"
Depth [D]	4.63"
Height [H]	4.96"
Screw Diameter [Sc]	M5
Unit Weight	0.22 lb
Certifications	CE EAC 8546901000 (Russian Federation) IEC 61439-1 Busbar Supports RoHS

Part Number	BS-125A
Standard Packaging Quantity	10 pc
UPC	78285687623
EAN-13	3479775513119

Must be used with copper busbars.

IEC is a registered trademark of the International Electrotechnical Commission. UL, UR, cUL, cUR, cULus and cURus are registered certification marks of UL LLC.

© 2019 nVent All rights reserved
nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.
All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.