

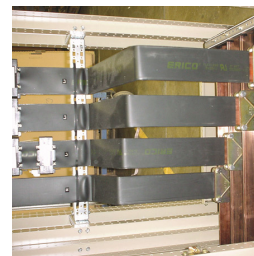
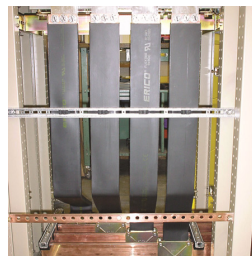
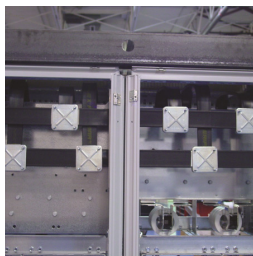


# BC Ribbed Steel Busbar Clamp – BC40 (553210)

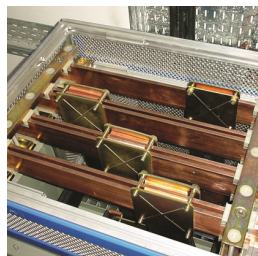

- Connects two copper busbars together or nVent ERIFLEX Flexibar to copper busbar
- Two ribbed plates complete with screws
- Allows for excellent electrical contact
- Installs quickly and easily
- Ideal for on site modifications
- RoHS compliant

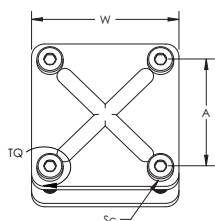

Part Number	BC40
Article Number	553210
Material	Steel
Finish	Electrogalvanized
Clamping Capacity	0.79"
Busbar Width	1.57"
Width (W)	2.6"
A	2.05"
Screw Diameter (Sc)	M6
Torque (TQ)	5.16 ft lb
Unit Weight	0.81 lb
Certifications	EAC 8536900100 (Russian Federation) RoHS UR
Standard Packaging Quantity	8 pc
UPC	78285644983
EAN-13	3479775532103

Clamping capacity is calculated using included screws. Maximum clamping capacity is 50 mm (1.97") using longer SAE Grade 5 screws.

UL, UR, cUL, cUR, cULus and cURus are registered certification marks of UL LLC.

© 2019 nVent All rights reserved  
nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.  
All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.