

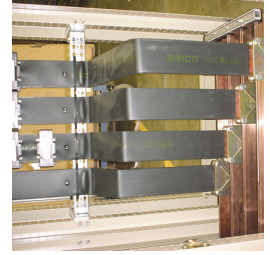
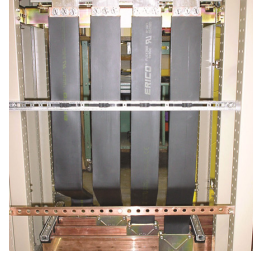
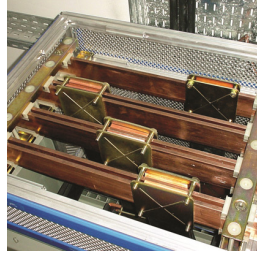


BC Ribbed Steel Busbar Clamp – BC80 (553250)

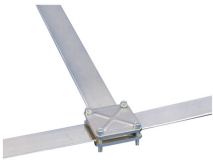

- Connects two copper busbars together or nVent ERIFLEX Flexibar to copper busbar
- Two ribbed plates complete with screws
- Allows for excellent electrical contact
- Installs quickly and easily
- Ideal for on site modifications
- RoHS compliant

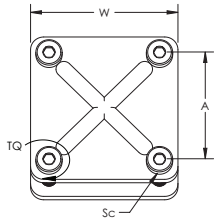

Part Number	BC80
Article Number	553250
Material	Steel
Finish	Electrogalvanized
Clamping Capacity	0.79"
Busbar Width	3.15"
Width (W)	4.65"
A	3.78"
Screw Diameter (Sc)	M10
Torque (TQ)	29.5 ft lb
Unit Weight	2.6 lb
Certifications	EAC 8536900100 (Russian Federation) RoHS UR
Standard Packaging Quantity	4 pc
UPC	78285644980
EAN-13	3479775532509

Clamping capacity is calculated using included screws. Maximum clamping capacity is 50 mm (1.97") using longer SAE Grade 5 screws.

UL, UR, cUL, cUR, cULus and cURus are registered certification marks of UL LLC.

© 2019 nVent All rights reserved
nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.
All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.