

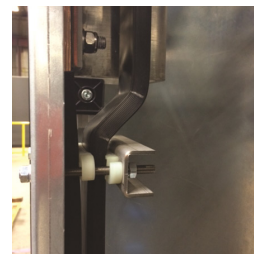
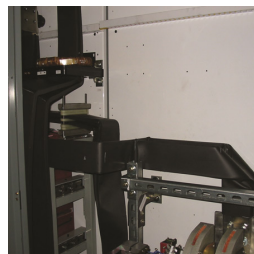
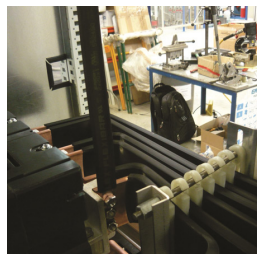


RFS Reinforced nVent ERIFLEX Flexibar Support – RFS40-63 (553370)

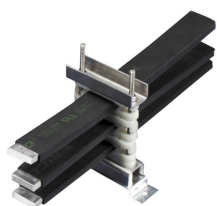

- Supports up to eight conductors in parallel
- Ensures correct spacing for optimum cooling
- Easy to install
- Spacers are halogen free
- RoHS compliant

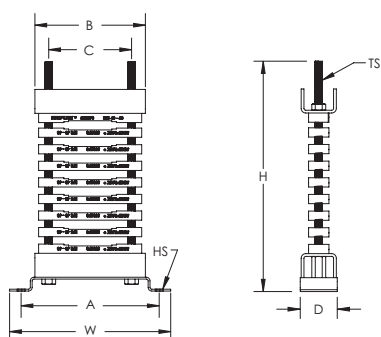

Part Number	RFS40-63
Article Number	553370
Material	Stainless Steel 304 (EN 1.4301) Polyamide
Conductor Width	1.57" – 2.48"
Depth (D)	1.57"
Height (H)	8.26"
Width (W)	6.89"
Hole Size (HS)	0.35"
Thread Size (TS)	M8
A	5.9"
B	4.72"
C	3.54"
Unit Weight	2.05 lb
Certifications	EAC 8546901000 (Russian Federation) RoHS

Part Number	RFS40-63
Standard Packaging Quantity	1 pc
UPC	78285657831
EAN-13	3479775533704

Recommended distance between supports is 400 mm (15 3/4").

© 2019 nVent. All rights reserved.
nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.
All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.