

 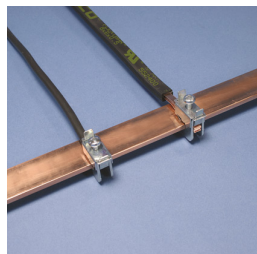
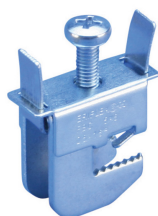


# FBC nVent ERIFLEX Flexibar/Cable to Busbar Clamp – FBC10X6 (553430)



- Very compact clamp for connecting cable conductors or nVent ERIFLEX Flexibar to busbar without drilling
- Conductor is clamped with a pressure plate
- Clamps can be mounted and slid into position on busbar prior to connecting conductors
- Connections can be added after busbar has been mounted
- Single screw locks clamp and makes connection
- EAC compliant
- RoHS compliant

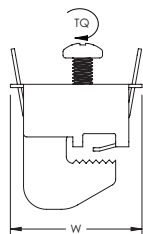

Part Number	FBC10X6
Article Number	553430
Material	Steel
Finish	Electrogalvanized
Busbar Thickness	0.39"
Complies With	IEC® 60999
Conductor Size	2.5 mm <sup>2</sup> Stranded - 16 mm <sup>2</sup> Stranded
Conductor Width	0.24"
Depth (D)	0.55"
Height (H)	1.3"
Width (W)	1.22"
Torque (TQ)	2.21 ft lb
Unit Weight	0.066 lb
Certifications	EAC 8536900100 (Russian Federation) RoHS
Standard Packaging Quantity	15 pc
UPC	78285687691
EAN-13	3479775534305

Conductor must be stripped at least a distance equal to the width of the clamp.

IEC is a registered trademark of the International Electrotechnical Commission.

© 2019 nVent All rights reserved  
nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.  
All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.