

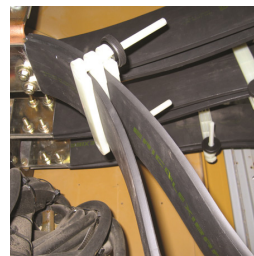


FS Spacer Clamp – FS40-63 (553570)

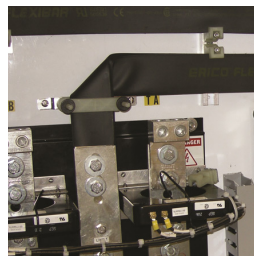

- Provides support for nVent ERIFLEX Flexibar and insulated braided conductors without damaging the insulation
- Ensures correct spacing for optimum cooling
- Supports up to four conductors in parallel
- Easy to install
- Spacers are halogen free
- RoHS compliant

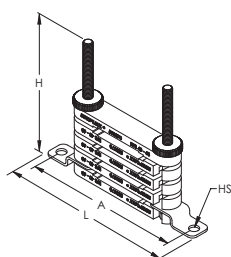

Part Number	FS40-63
Article Number	553570
Finish	Electrogalvanized
Material	Steel Polyamide
Working Temperature	-40 to 266 °F
Flammability Rating	UL® 94HB
Conductor Width	1.57" – 2.48"
Height (H)	3.74"
Length (L)	6.54"
Hole Size (HS)	0.33"
A	5.9"
Unit Weight	0.22 lb
Certifications	EAC 8546901000 (Russian Federation) RoHS UR
Standard Packaging Quantity	10 pc
UPC	78285644976
EAN-13	3479775535708

Recommended distance between supports is 400 mm (15 3/4").

UL, UR, cUL, cUR, cULus and cURus are registered certification marks of UL LLC.

© 2019 nVent All rights reserved
nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.
All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.