

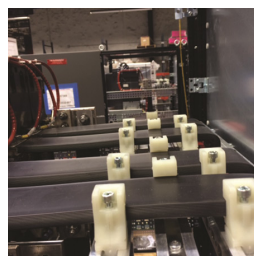


UFS nVent ERIFLEX Flexibar and IBSB Support Kit – UFS-KIT (553590)

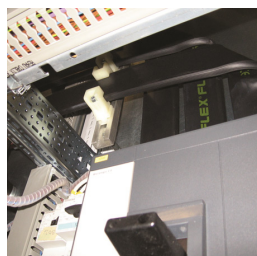

- Kit includes one rail and 24 retaining blocks
- Create up to three 650 mm [25.6"] supports capable of holding four nVent ERIFLEX Flexibar
- Retaining blocks are halogen free
- RoHS compliant

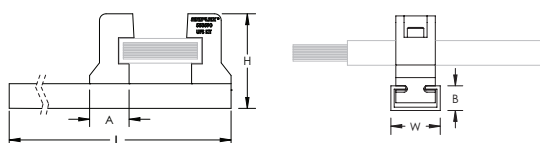

Part Number	UFS-KIT
Article Number	553590
Material	Aluminum Polyamide
Conductor Thickness	0.08" – 0.31"
Conductor Width	0.61" – 4.72"
Height (H)	2.27"
Length (L)	6.56'
Width (W)	1.18"
A	0.95"
B	0.59"
Unit Weight	5.07 lb
Certifications	EAC 8546901000 (Russian Federation) RoHS UR
Standard Packaging Quantity	1 pc
UPC	78285644975
EAN-13	3479775535906

Recommended distance between supports is 400 mm [15 3/4"].

UL, UR, cUL, cUR, cULus and cURus are registered certification marks of UL LLC.

© 2019 nVent All rights reserved
nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.
All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.