

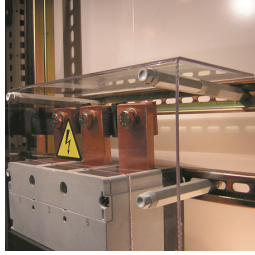


DH Distance Holder and Spacer – DH85M5 (560640)

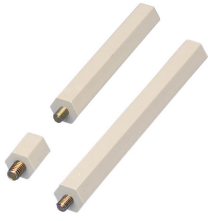

- To make higher plates, screens or profiles
- Male-female allowing stable mounting
- Electrotechnical applications

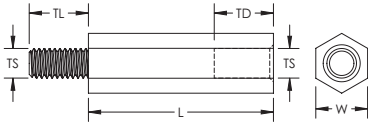

Part Number	DH85M5
Article Number	560640
Material	Steel Polystyrene
Finish	Electrogalvanized
Insulation Voltage	1,000 V
Temperature	176 °F Max
Flammability Rating	UL® 94HB
Thread Size (TS)	M5
Thread Length (TL)	0.28"
Thread Depth (TD)	0.28"
Length (L)	3.346"
Width (W)	0.512"
Unit Weight	0.037 lb
Certifications	RoHS
Standard Packaging Quantity	100 pc
UPC	78285687740
EAN-13	3479775606408

UL, UR, cUL, cUR, cULus and cURus are registered certification marks of UL LLC.

© 2019 nVent All rights reserved
 nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.
 All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.