


CAPB Cap Nut with Threaded Stud – CAP-CAPB5 (560840)

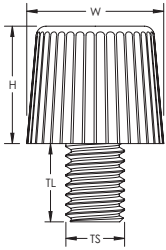

Part Number	CAP-CAPB5
Article Number	560840
Material	Steel Polystyrene
Finish	Electrogalvanized
Temperature	176 °F Max
Flammability Rating	UL® 94HB
Thread Size (TS)	M5
Thread Length (TL)	0.31"
Height (H)	0.472"
Width (W)	0.551"
Unit Weight	0.009 lb
Certifications	RoHS
Standard Packaging Quantity	100 pc
UPC	78285687752
EAN-13	3479775608402

UL, UR, cUL, cUR, cULus and cURus are registered certification marks of UL LLC.

© 2019 nVent All rights reserved
 nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.
 All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.