


# PBC Braided Power Shunt – PBC1200X500 (564030)



- Ideal for transformer-busduct link
- Solid palms can be drilled to fit customer specific designs
- Extra flexible power connection and good resistance to vibration

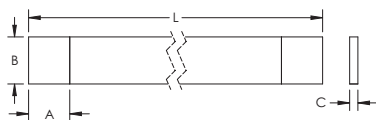

Part Number	PBC1200X500
Article Number	564030
Material	Copper
Finish	Tinned
Wire Diameter	0.006"
Cross Section	2,368.23 kcmil
$\Delta T$ 30 K	1,982 A
$\Delta T$ 50 K	2,626 A
Length (L)	19.7"
A	4.92"
B	4.72"
C	0.69"
2 Bar Current Coefficient	1.6
Unit Weight	15.785 lb
Certifications	EAC 741300009 (Russian Federation) RoHS
Standard Packaging Quantity	1 pc
UPC	78285685475
EAN-13	3479775640303

When used in parallel, the two shunts must be spaced with a minimum distance equal to the thickness of the shunt to allow air cooling.

© 2019 nVent All rights reserved  
nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.  
All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.